
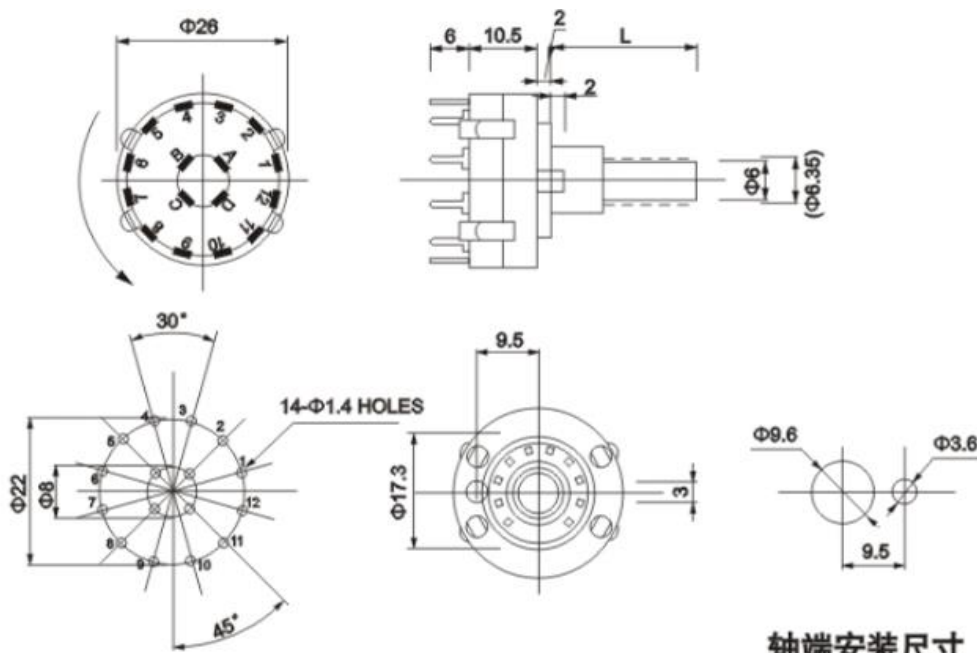


ROTARY SWITCH

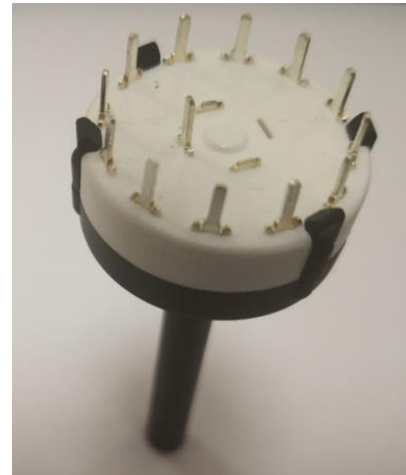


线路板开孔尺寸
The tapping size of circuit board

轴端安装尺寸
The fitting size of shaft end

Data Sheet

Shaft type: R

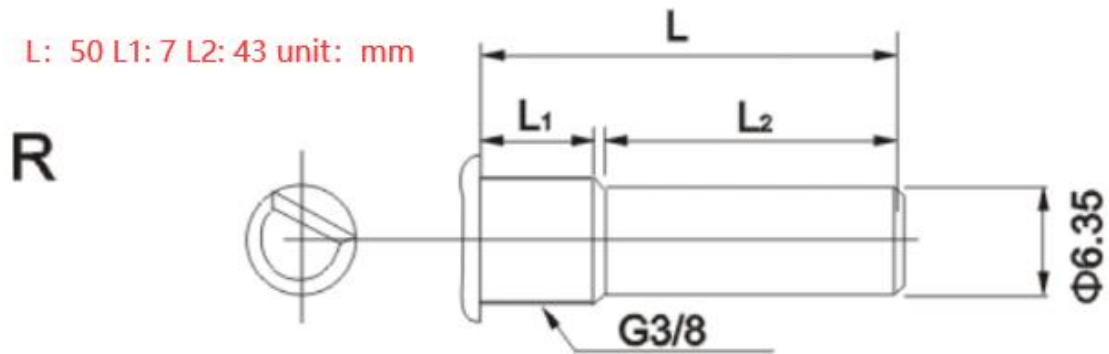

Technical data

Switch Rating	150mA at 250VAC/DC 300mA at 125VAC/DC
Contact resistance	$\leq 0.05\Omega$ (initial)
Insulation Resistance	DC 500V-1000M Ω Min
Limited voltage	AC 500V-1Min
Proof voltage	1,000 VAC(initial)
Rotation torque	4.9-24.5 N.cm
End stop strength	49 N.cm
Mechanical endurance	≥ 10000 cycles
Ambient temperature	-21 $^{\circ}$ C~70 $^{\circ}$ C
Welding hear-resistant property	260 $^{\circ}$ C/2.5 \pm 0.5S