
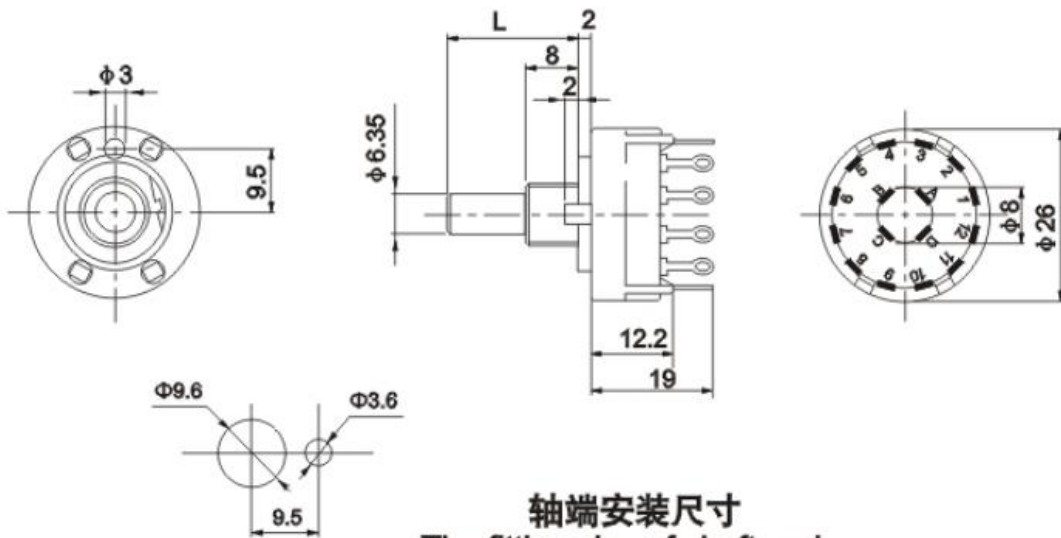


## ROTARY SWITCH

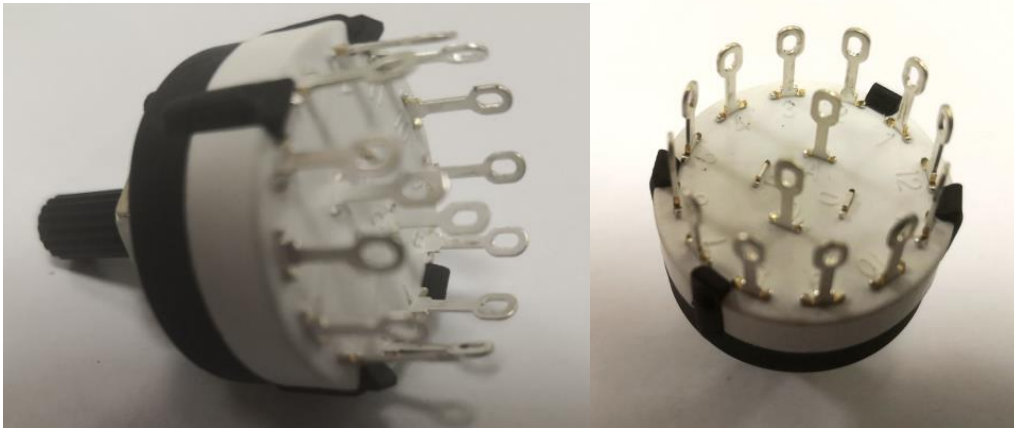

轴端安装尺寸  
The fitting size of shaft end

## Data Sheet


Shaft type: 18T

L: 20

L1: 3

L2: 17 unit: mm

18T

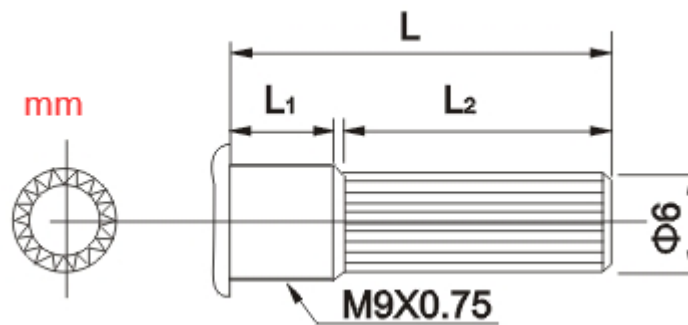

## Technical data

Switch Rating	150mA at 250VAC/DC 300mA at 125VAC/DC
Contact resistance	≤0.05Ω (initial)
Insulation Resistance	DC 500V-1000MΩ Min
Limited voltage	AC 500V-1Min
Proof voltage	1,000 VAC(initial)
Rotation torque	4.9-24.5 N.cm
End stop strength	49 N.cm
Mechanical endurance	≥10000cycles
Ambient temperature	-21°C~70°C
Welding hear-resistant property	260°C/2.5±0.5S