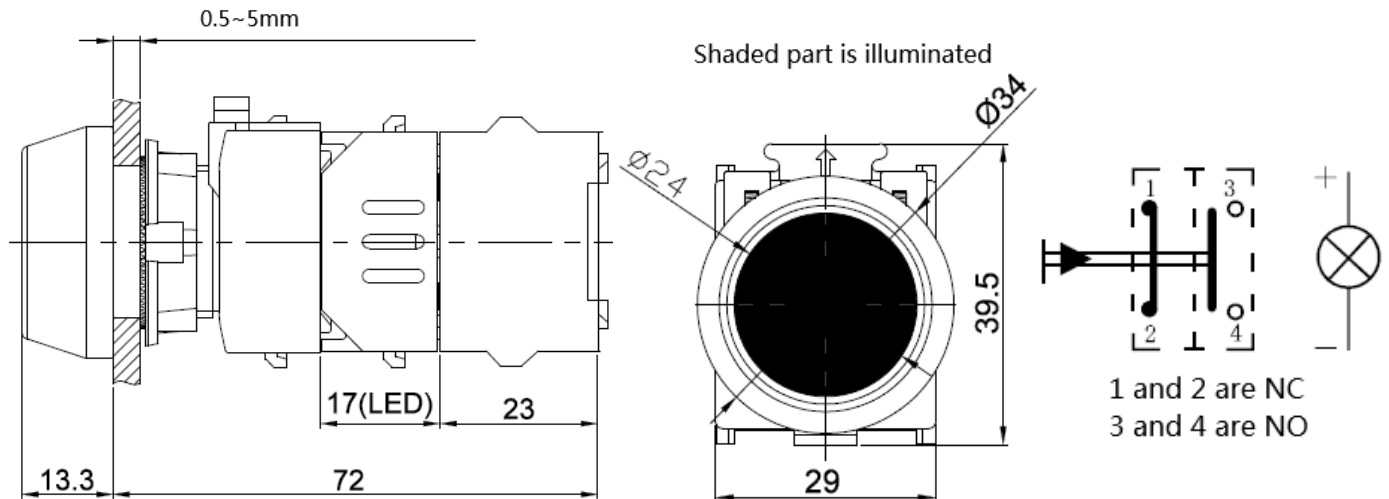


Push button switch**Version 03/29****Specification**

Mounting diameter.....	22 mm
Head shape	Round head
Operation type.....	Momentary/latching
Illumination	Full actuator
Contact structure	1NO1NC
Switch rating.....	Ue:250V Ie:5A
Terminal	Screw terminal
Operating and storage temperature	-25 to +55°C
Operating and storage humidity	45 to 85 % RH
IP rating.....	IP40

Item no.	Operation type	LED color	LED voltage
2357027	Momentary	Red	12 V
2357028	Momentary	Green	12 V
2357029	Momentary	Blue	12 V
2357030	Latching	Red	12 V
2357031	Latching	Green	12 V
2357032	Latching	Blue	12 V