


Data Sheet

Push button switch

Version 04/25

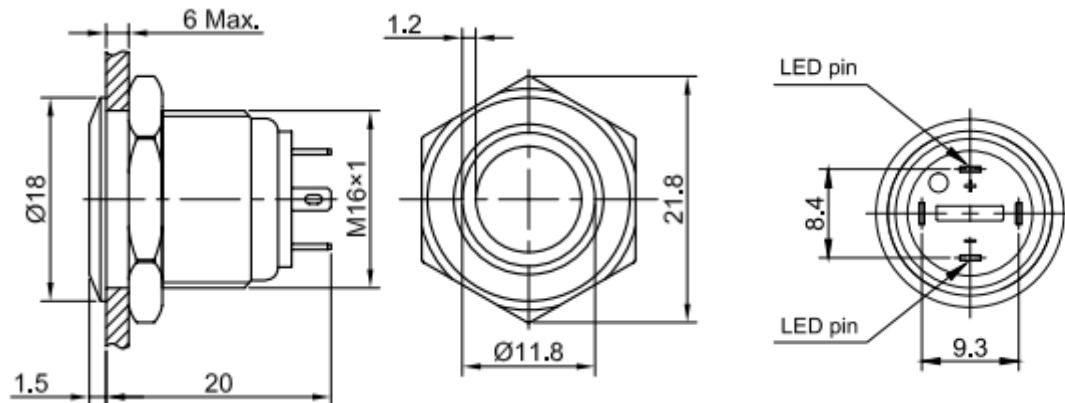

6 MAX: means the panel thickness, the max thickness for the panel no more than 6mm.

Specification

Mounting diameter.....	16 mm
Head shape	Flat round head
Operation type.....	Momentary
Contact structure	1NO
Switch rating.....	2A/48VDC
Illumination type	Ring
Terminal	Soldering Pins
Body material	Black aluminium alloy
Operating and storage temperature	-25 to +55°C
Operating and storage humidity	45 to 85 % RH
Base material	PA
IP rating	IP65

Item no.	LED color	LED voltage
2357040	Red	12 V
2357041	Blue	12 V
2357042	Green	12 V