



BRAUN

Pulse oximeter 1 Pulsoximeter 1

YK-81C

Installing batteries
Batterien einlegen

Initial set up Erste Einrichtung

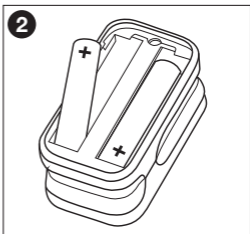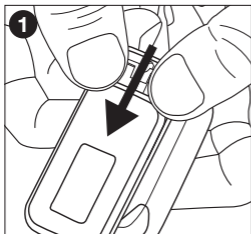

Pulse oximeter 1 – Isætning af batterier – Indledende opsætning
Pulsioxímetro 1 – Instalación de las baterías – Configuración inicial
Pulssioksimetri 1 – Paristojen asentaminen – Alkuasetus
Oxymètre de pouls 1 – Installation des piles – Configuration initiale
Παλμικό οξύμετρο 1 – Τοποθέτηση μπαταριών – Αρχική ρύθμιση
Pulsossimetro 1 – Installazione batterie – Impostazione iniziale
Saturatiemeter 1 – Batterijen plaatsen – Eerste keer instellen
Pulsoksymeter 1 – Sette inn batterier – Innledende oppsett
Pulsoksymetr 1 – Wkładanie baterii – Przygotowanie do pracy
Oxímetro de pulso 1 – Colocar as pilhas – Instalação inicial

مقياس التأكسج النبضي 1 - تركيب البطاريات - الإعداد الأولي

Pulsoximeter 1 – Sätta i batterier – Initial installation
Pulse oksimetre cihazı 1 – Pillerin takılması – İlk kurulum

Helen of Troy

Creative Department Artwork Specifications

Brand: Braun
Category: Oximeter
Model: **YK-81C**
Artwork Part #: A005656R0
Die Line Part #: NA
Subject: Owners Manual - Insert
Region: EMEA
Flat Size: **MM: W80 x H154**
Scale: 1/1
Material: 50# matte text
Page count: NA
Revision: 2
Date: **14DEC20**
Release Date: 16DEC20
Rerelease Date:

Colors:

Dielines (Do not print)

Spot Colors

Cyan
0%

Magenta
0%

Yellow
0%

Black
100%

PMS
XXXX

PMS
XXXX



Special Instructions:

Quality Requirement of Artwork and Quality
Clarification Process of Artwork Printing:
Meet Eng-QS-06&02

Helen of Troy
Creative Services
Marlborough, MA 01752 USA
+1 508 490 7000