
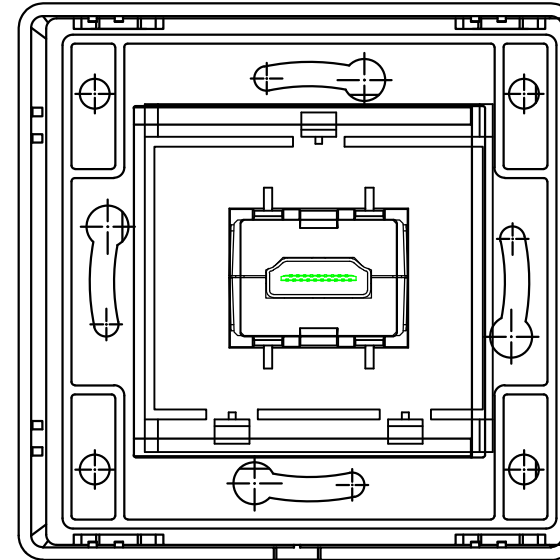


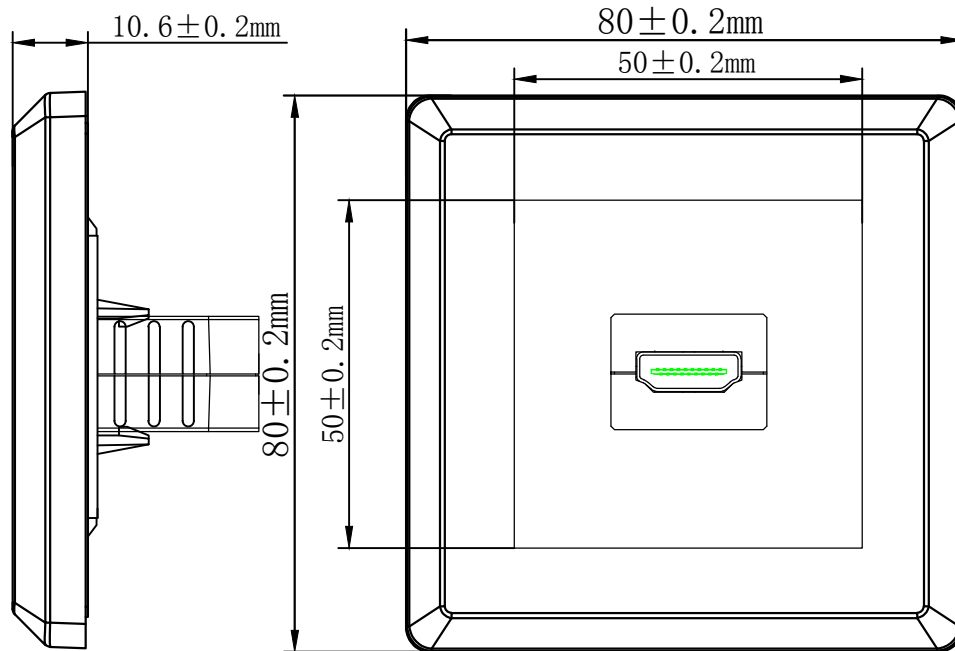

PIN OUT			
J1		J2	
1	_____	1	
3	_____	3	
2	_____	2	
4	_____	4	
6	_____	6	
5	_____	5	
7	_____	7	
9	_____	9	
8	_____	8	
10	_____	10	
12	_____	12	
11	_____	11	
13	_____	13	
14	_____	14	
15	_____	15	
16	_____	16	
17	_____	17	
18	_____	18	
19	_____	19	
Shell		Shell	

NOTE:

1.Electrical test:

- (1).100% open short & miss wire test;
- (2).Insulation resistance:DC 200V 10M ohm;
- (3).Contactor resistance:3 ohm;
- (4).Dielectric strength:300V AC/Sec, 2mA.

Suppor 4K*2K@60HZ

OPERATING TEMPERATURE: $0^{\circ}\text{C} \sim 45^{\circ}\text{C}$

STORAGE TEMPERATURE: $-20^{\circ}\text{C} \sim 70^{\circ}\text{C}$

OPERATION HUMIDITY:10%~85%

STORAGE HUMIDITY:10%~85%

MATERIAL LIST:

④	Outer Face plate	ABS 80*80MM White RAL 9003	1	
③	Bracket	SECC T1.2mm	1	
②	Inner Face plate	ABS 50*50MM White RAL 9003	1	
①	HDMI Adapter	HDMI A Female/Female 180 degree, PIN Gold plating, Shell Gold plating	1	
NO.	PARTS NAME	SPECIFICATION STANDARD	QT' Y	REMARK

RoHS 2.0 And REACH Compliant
packing: 1pc/neutral box+label

						Renkforce					
						CUSTOMER	CN	ITEM NO.	29212c177		
						PRODUCT NAME	HDMI 2.0a AF-AF Adapter with Faceplate Germany Type	UNO ITEM NO.	255181	UNIT	MM
								APPOBY	DATE		
BY	CHK									2018-06-01	

NEW

2018-06-01

A

DRAWNBY

CHECKBY

APPOBY

DATE

Alvan

Alvan

2018-06-01

REVISION RECORD MODIFICATIONS

DATE

REV.