 




WIRING DIAGRAM

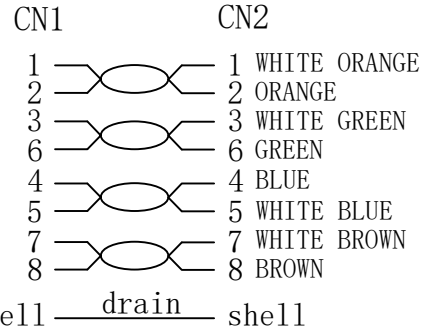

NOTE:

1. 100% OPEN SHORT, MISS WIRE TEST
2. PRINT WORD:  
F/UTP CAT. 5E 26AWG×4P PATCH ISO/IEC 11801 & EN50173 VERIFIED
3. Fluke Test:  
TEST LIMIT:ISO 11801 Channel Class D
4. Working temperature:-10°C+ 60°C  
Storage temperature:-20°C+ 75°C  
Operation humidity:10%~85%  
Storage humidity:10%~85%
5. ROHS 3.0 AND REACH COMPLIANT

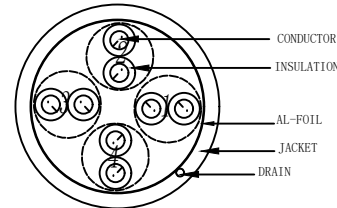

MATERIAL LIST

③	OVER MOLD	PVC 75A COLOR:Grey (RAL7035)	2	
②	CONNECTOR	RJ45 8P8C Shielded Plug, Pin plated gold 3u, shell plated nickel, Transparence (UL 94-V2)	2	
①	CABLE	F/UTP CAT. 5e (26AWG BC*1P)*4PAIRS+FOIL+DRAIN+ JACKET:PVC COLOR:Grey (RAL7035), OD: 5.0±0.2MM	1	
NO.	PARTS NAME	SPECIFICATION STANDARD	QT' Y	REMARK
		NEW	2023-05-15	A
BY	CHK	REVISION RECORD MODIFICATIONS	DATE	REV.

Renkforce				
CUSTOMER		BN.	2362828	
PRODUCT NAME	Cat. 5E F/UTP Premium Patch cord PVC		UNIT	MM
DRAWNBY	CHECKBY	APPOBY	DATE	
Hasia	Alvan		2023-05-15	