


Model No.: **GP25A**

NO MERCURY ADDED	
Description	: Mercury Free Alkaline Manganese Battery, AAAA Size
Chemical System	: Alkaline Manganese
Nominal Voltage	: 1.5 Volts
Nominal Dimensions	: Ø8.3 mm x 42.5 mm
Terminals	: Protruded positive(+) and flat negative(-) contacts
Jacket	: Foil jacket
Applications	: All electronic devices, e.g. toys, photographic equipment, data banks, calculators, audio appliances, remote controls, paging machines.
Average Weight	: 6.8g


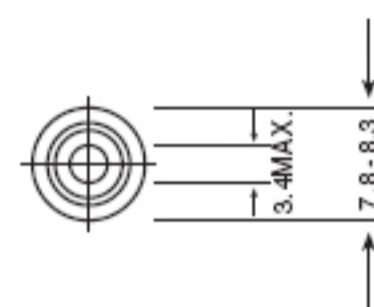


Cross References:

GP	ANSI	IEC	Energizer	Duracell
25A	LR6	LR8D425	E96	MX2500

Typical Service Life:

Discharge Resistance	Discharge Condition	End Point Voltage	Service Life
35mA	24 Hrs/ Day	0.9V	15 Hrs

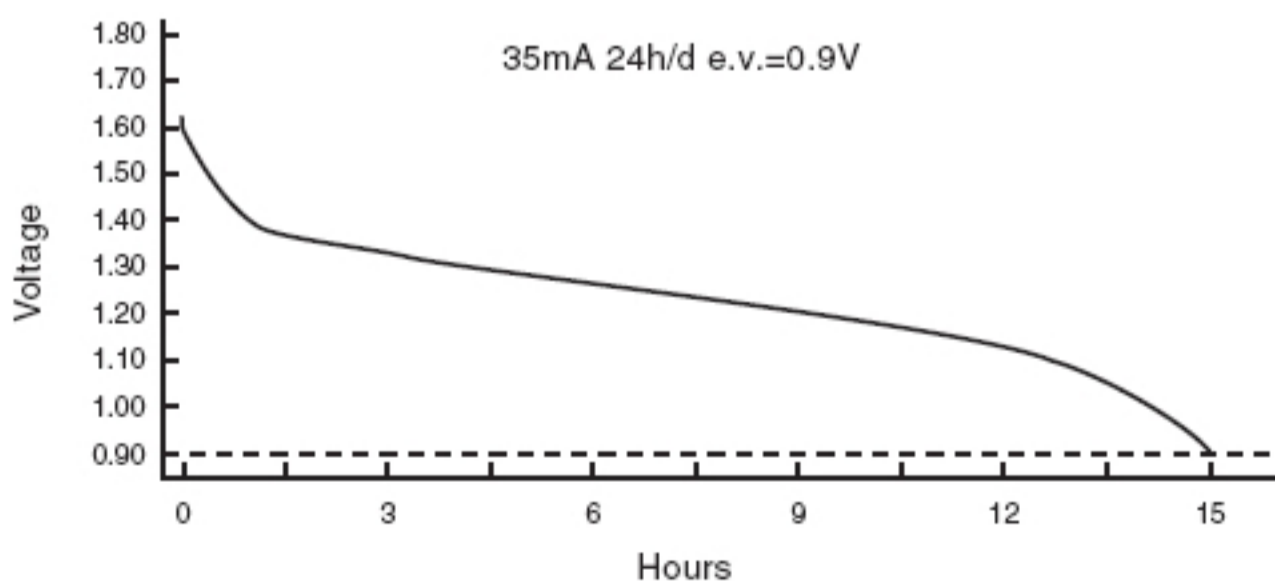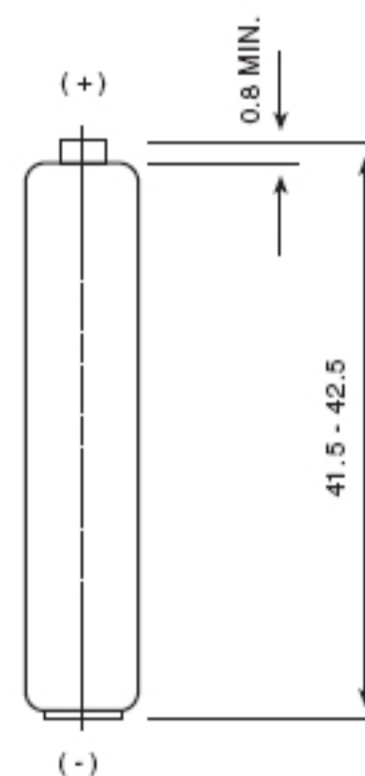

Unit : mm

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.

www.gpbatteries.com

Manufacturer reserves the right to alter or amend the design, model and specification without prior notice.
Copyright © GPI International Ltd. - All rights reserved

Member
Gold Peak Group

0511011056