



TECHNICAL INFORMATION

Watts:	120
Lumens:	16800
Input Power:	AC:176-305V, 50Hz
Long Life:	30,000 Hours
Unit Color:	Grey
Body Type:	Aluminum
PF:	>0.9
LED Chip Type:	SMD-Samsung Chip
CRI:	>70
Operation Temperature:	-20°C to +45°C
Dimmable:	Yes
Beam Angle:	153x70°
Color Temperature:	5700K
Dimension:	656.4x270x85mm
Output Voltage:	40-114VDC
Output Current:	1050-1500mA


140 LUMENS STREETLIGHTS

V-TAC's LED Lighting range includes lighting that fulfills the needs of various end-users and industries, offering efficient and innovative products that provide modern solutions at an affordable price. We are proud to also provide an extended multi-year warranty on our products, as well as detailed support.

One brand, endless solutions..

SKU: 886 - 1580 939

[View more details](#)

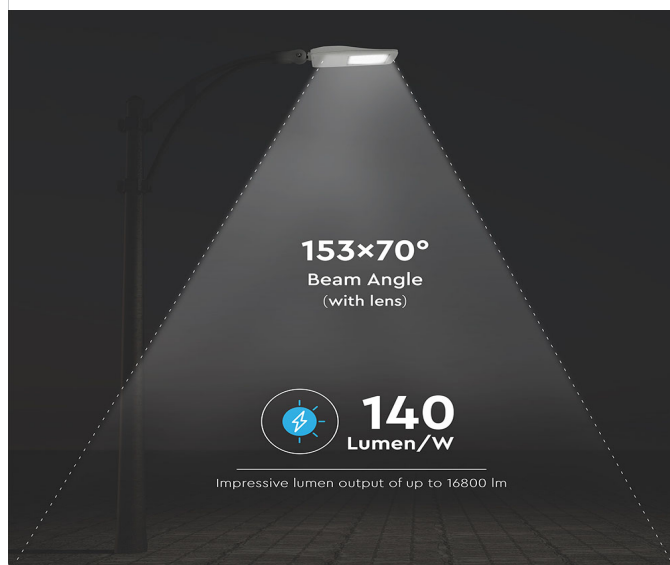

FEATURES

- Powerful LED light source with lumen efficiency of 140 LM/W
- Fitted with high efficiency Samsung LED Chips that offer up to 85% in energy savings
- Adjustable adaptor with mounting diameter of 60mm
- Designed with Inventronics driver
- Designed with Class II and Type III Lens with beam angle of 153x70°
- Suitable for industrial usage, warehouses, highways etc.

CE/EMC

CE/LVD



PACKAGING

Gross Weight (Kgs):	6.4
Unit CBM:	0.033228
Dimension:	656.4x270x85mm

MASTER BOX PACKAGING

Box Qty:	2
Qty Per Pallet:	40
Length (Box) mm:	355
Width (Box) mm:	720
Height (Box) mm:	130

LISTING DETAILS

Commodity Code:	9405403990
Ean Code:	3800157646048