


Data Sheet

DC 2.1 Male DC Jack Quick Terminal Adapter (w/o screw)

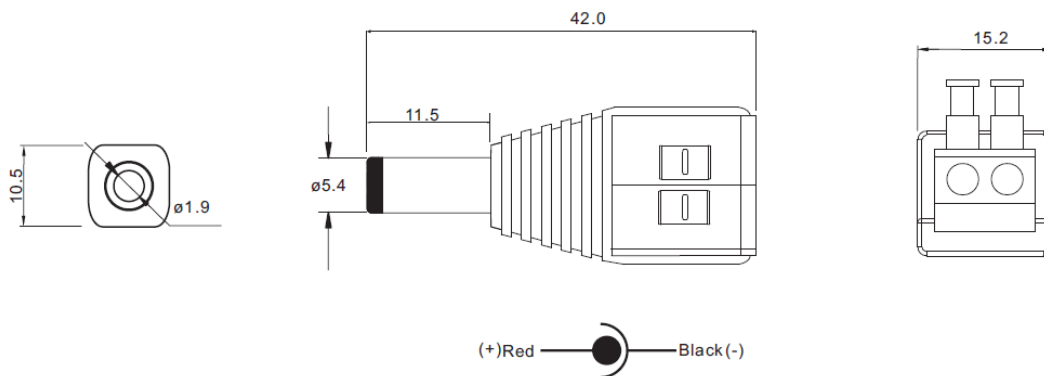

TOLERANCE		
X	±0.50	
X.X	±0.30	
X.XX	±0.20	
X'	±1°	
UNIT:	mm	REV.: A
SCALE:	4/1	PAGE: 1/1

Technical Data:

Electrical:

Voltage rating: 12 V/DC

Current rating: 5A

Contact resistance: 20mΩ

Insulation resistance: 5000 MΩ/ 1000 V

Wire range: 22-16 AWG (0.325mm² to 1.308mm²)

Mechanical:

Torque: 0.5 Nm (4.4 lb/in)

Operating temperature: -40°C to 105°C

Strip length: 8-9 mm