


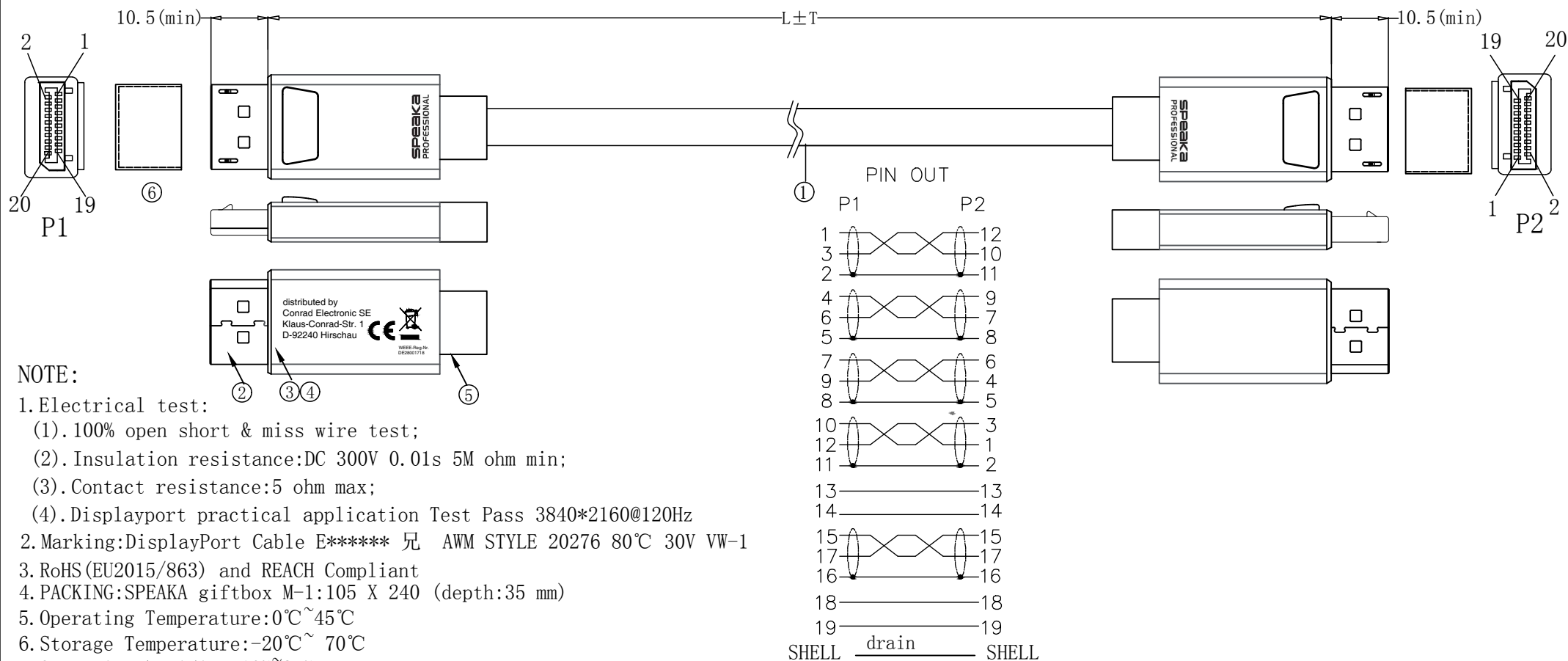

NOTE:

1. Electrical test:

- (1). 100% open short & miss wire test;
- (2). Insulation resistance: DC 300V 0.01s 5M ohm min;
- (3). Contact resistance: 5 ohm max;
- (4). Displayport practical application Test Pass 3840*2160@120Hz
2. Marking: DisplayPort Cable E***** 兄 AWM STYLE 20276 80°C 30V VW-1
3. RoHS(EU2015/863) and REACH Compliant
4. PACKING: SPEAKA giftbox M-1: 105 X 240 (depth: 35 mm)
5. Operating Temperature: 0°C ~ 45°C
6. Storage Temperature: -20°C ~ 70°C
7. Operation humidity: 10% ~ 85%
8. Storage humidity: 10% ~ 85%

MATERIAL LIST:

⑤	DUST CAP	LD PE	2	
④	TUBE END	BLACK PVC 45P	2	
③	HOUSING	Aluminium Cool Gray 11C	2	
②	CONNECTOR	DP 20P/MALE BLACK INSULATION, THE PIN GOLD PLATED , THE SHELL FOR GOLD PLATED	2	
①	CABEL	DP1.4V CABLE[(30AWG BC)*1P+D(30AWG BC)+FAM]*5+(30AWG BC)*4C+AL-FOIL+(30AWG BC)+BRAID, JACKET: 90P PVC black OD: 6.0±0.2mm	1	

ITEM NO.	LENGTH
2377612	1000±20mm
	1500±30mm
2377614	2000±30mm
2377613	3000±50mm

NO.	PARTS NAME	SPECIFICATION DESCRIPTION	QT' Y	REMARK	CUSTOMER	CN	ITEM NO.	SEE THE CHART
					PRODUCT NAME	DP1.4V Male-Male Cable Gray Aluminium Housing 30AWG		791108PLX
		NEW	2021-04-02	A0	DRAWNBY	CHECKBY	APPOBY	UNIT
BY	CHK	REVISION RECORD MODIFICATIONS	DATE	REV.	Alvan	Alvan		2021-04-02