

## DATASHEET

Item No.: 2377792

Type designation: LR6 Common: AA

Chemical system: Alkaline

Nominal voltage: 1.5 V


Weight: Approximate 23.8 g

Dimension (mm)

The dimensions shall be in accordance with the below figures both prior to and after the service output test.

Measuring equipment shall be with a minimum accuracy of  $\pm 0.05\text{mm}$ .

/	min	max
$\Phi$	13.7	14.5
A	49.5	50.5
C	7.0	-
F	-	5.5
G	1.0	-

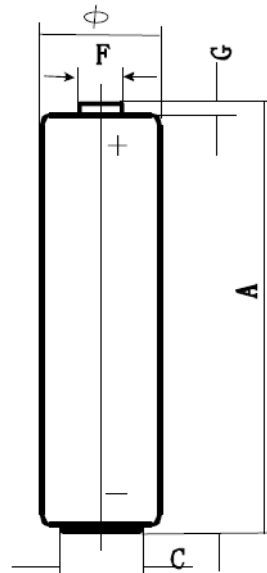

Capacity: 3000 mAh (10 mA, 24 h/d, 20°C, e.v.= 0.8 V)

Operating temperature: -18 °C ~ +50 °C

Recommended temperature: +10°C ~ +25°C

Recommend storage temperature:  $\leq 30^\circ\text{C}$

Shelf lifetime: 7 Years