

Inductive proximity sensor detection switch LJ12A3-4-ZBX



Specifications:

Model: LJ12A3-4-ZBX

Wire shell material: PVC

Sensor shell material: Nickel plated brass

Cable length: Approx. 110cm / 3.6ft

Dimension: M12 x 6cm (2.4inch)

Type: NPN

Detection Distance: 4mm / 0.15inch

Switch appearance Type : Cylinder type

Working voltage: DC 6-36V

Continuous current: 300mA

Short circuit protection: No

Polarity Protection: Yes

Protection grade: IP65


Output indication: Red light

Working temperature: -25-70°C

Connection way: 3-wire PVC cable

产品尺寸

PRODUCT SIZE

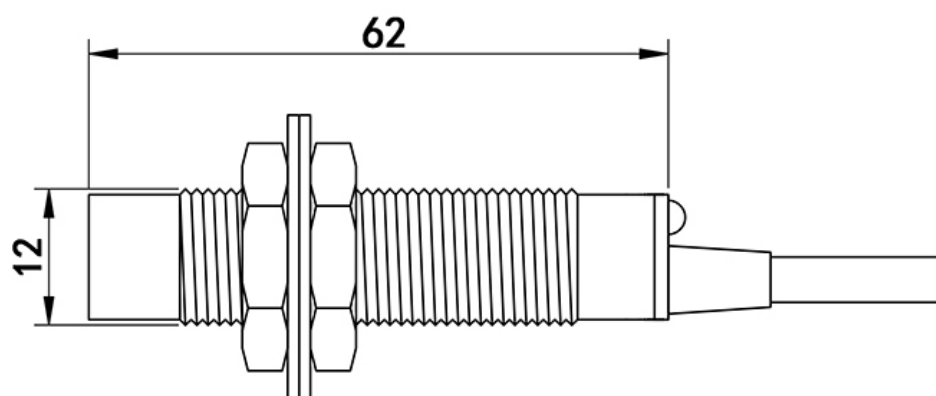

非埋入式