


Cabinets - Wall Mounting Network Cabinets

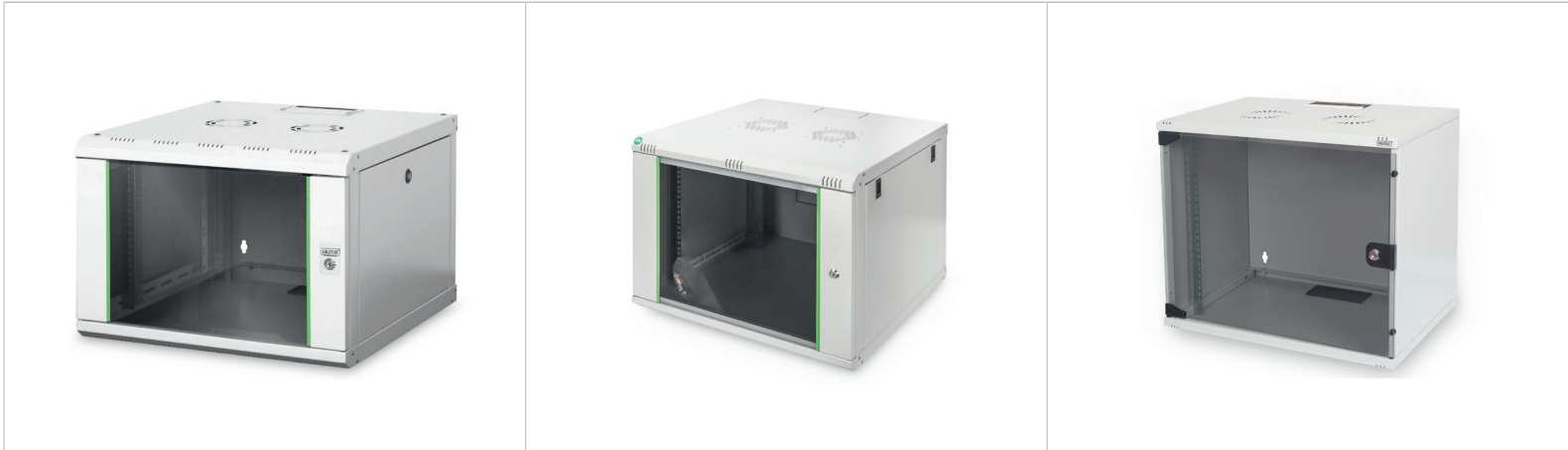

Part number (example)		DN-19 07U-6/6	DN-19 07U-6/6-EC	DN-19 07U-S-1
Series		Unique	Dynamic Basic	SOHO
Standard sizes	Height units (U)	7U, 9U, 12U, 16U, 20U	7U, 9U, 12U, 16U	7U, 9U, 12U
	Width (mm)	600	600	540
	Depth (mm)	450, 600	450, 600	400
Shipping style	Shipping style	Mounted	Mounted	Unmounted (Flatpack)
Front door	Style	Lateral steel struts with safety glass, single opening	Lateral steel struts with safety glass, single opening	Safety glass, single opening
	Locking	Lock	Lock	Lock with plastic handle
	Opening angle	210°	235°	200°
Side panels	Side panels	Detachable, lockable	Detachable with snap-in latches	Fixed
Fan area in roof	Fan area in roof	Punched-out holes	Punched-out holes	Punched-out holes
Cable entries	Cable entry in top	Cut-out with sliding cover (145 x 50 mm)	Pre-punched (145 x 70 mm)	Cut-out with brush (145 x 70 mm)
	Cable entry in base	Cut-out with plastic cover (145 x 70 mm)	Pre-punched (145 x 70 mm)	Cut-out with plastic cover (145 x 70 mm)
	Cable entry on rear side	Cut-out with plastic cover (145 x 70 mm)	Pre-punched (350 x 100/240/380/380 mm)	⊗
482.6 mm (19") rails	Style	Cranked shape, with U numbers, adjustable	L-shape with U numbers, adjustable	L-shape, adjustable
	Quantity	2 (450 mm depth cabinets); 4 (600 mm depth cabinets)	2 (450 mm depth cabinets); 4 (600 mm depth cabinets)	2
	Load capacity	100 kg	60 kg	60 kg