

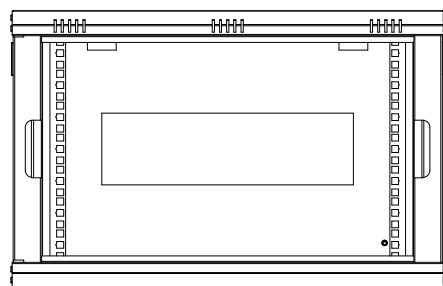


DN-19 07-U-EC	(4016032221692)
DN-19 07-U-EC-SW	(4016032257783)
DN-19 07U-6/6-EC	(4016032221739)
DN-19 07U-6/6-EC-SW	(4016032257790)
DN-19 09-U-EC	(4016032221708)
DN-19 09-U-EC-SW	(4016032257813)
DN-19 09U-6/6-EC	(4016032221746)
DN-19 09U-6/6-EC-SW	(4016032257806)


DN-19 12-U-EC	(4016032221715)
DN-19 12-U-EC-SW	(4016032257837)
DN-19 12U-6/6-EC	(4016032221753)
DN-19 12U-6/6-EC-SW	(4016032257820)
DN-19 16-U-EC	(4016032221722)
DN-19 16-U-EC-SW	(4016032257844)
DN-19 16U-6/6-EC	(4016032221760)
DN-19 16U-6/6-EC-SW	(4016032257875)

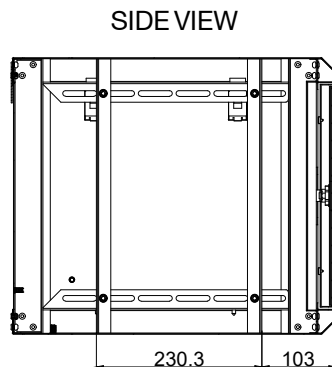


WIDTH OF WALL CABINET

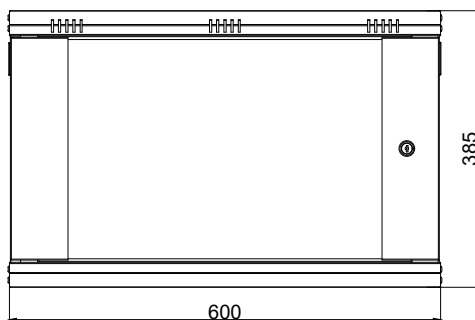



DEPTH OF WALL CABINET

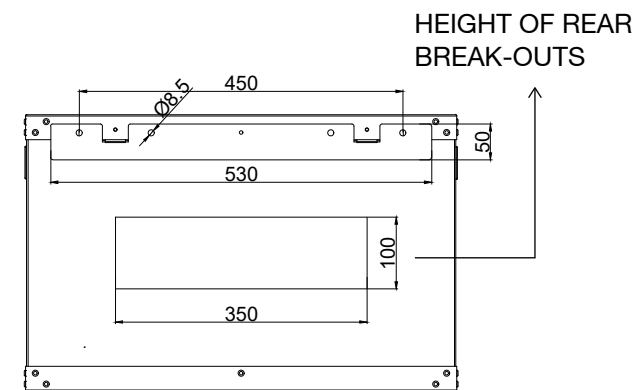

WIDTH OF HANGING HOLE

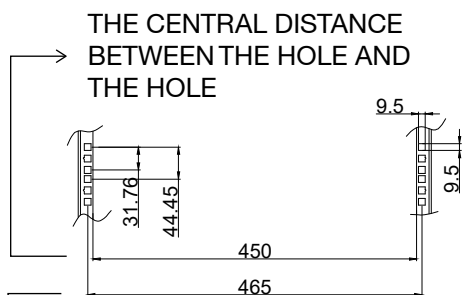

THE CENTRAL DISTANCE BETWEEN THE HOLE AND THE HOLE

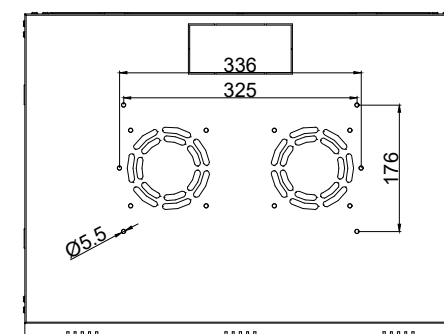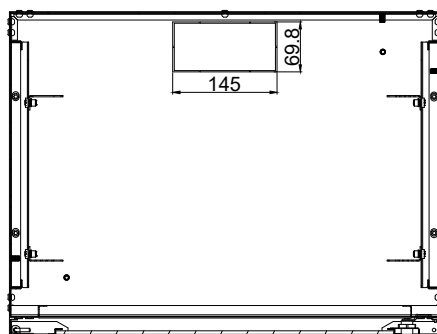

VENTILATION SLOT TYPE AND SIZES

7U-HEIGHT: 385 MM
 9U-HEIGHT: 474 MM
 12U-HEIGHT: 607 MM
 THICKNESS: 1.2 - 1.5 MM