



IPC-T22A

1080P H.265 Eyeball PoE Camera

IPC-T22A delivers 2MP live monitoring with a choice of 2.8/3.6/6mm lens option, it supports the latest H.265 compression which can save up to 50% bandwidth and storage. Human Detection allows you to monitor what matters without receiving annoying false alerts.



1080P Full HD Video

See more than 720P



Human Detection

Quickly find human targets in you home



Alarm Notification

Sends instant motion-activated alerts to your mobile phone



H.265 Codec

Save more high-quality video in less space



PoE

An Ethernet cable provide both data connection and electric power.



DIY Installation

Easy to install, simple to use




Diversified Storage

Supports NVR, Cloud Storage



24/7 Protection

Infrared night vision for clear-as-day clarity even in pitch dark

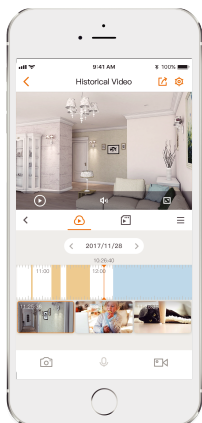

Stay close with what you care

With Cloud service, you will have access to what you care as long as Internet is available. You can record daily or motion videos on Cloud and playback anytime anywhere.

Specifications

Camera

1/2.8" Megapixel Progressive CMOS
2MP(1920 x 1080)
Night Vision: 30m(98ft) Distance
2.8/3.6/6mm Fixed Lens
Field of View: 2.8mm: 102° (H), 54° (V), 120° (D)
3.6mm: 89° (H), 46° (V), 108° (D)
6mm: 53° (H), 30° (V), 60° (D)

General

PoE Power Supply
Power Consumption:
Material: Plastic
Working Environment: -30° C~+60° C, Less Than 95%RH
CE, FCC

Network

1 x 100Mbps Ethernet Port
Imou App: iOS, Android
ONVIF

Video & Audio

Video Compression : H.265/H.264
Up to 25/30 fps Frame Rate
16x Digital Zoom

Notice Management

Motion Detection
Configurable Region
Human Detection

What's in the box

- 1x Camera
- 1x Quick Start Guide
- 1x Screw Package
- 1x Installation Position Map
- 1x Mounting Plate

