


## Data Sheet

### Insulated Crimp Fork Terminal Connector Set

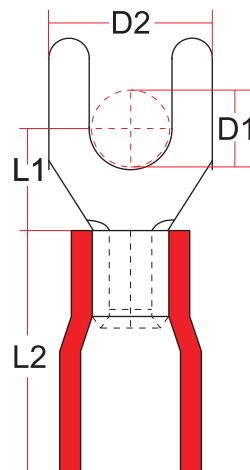

Insulator material: Vinyl (PVC)  
Terminal material: Tinned Copper  
Working Temperature: 75°C max.  
Rating voltage: 300 V/AC max.  
Rating current:  
Red - 10 Amp. max.  
Blue - 15 Amp. max.  
Yellow - 24 Amp. max.

Type	Dimension(mm)				Wire range	Color	Contents
	øD1	øD2	L1	L2			
T2010C299	3.2	6.4	6.5	10	0.5-1.5 mm <sup>2</sup> 22-16 AWG	Red	25pcs
T2010C300	3.7	6.4	6.5	10	0.5-1.5 mm <sup>2</sup> 22-16 AWG	Red	25pcs
T2010C301	4.3	7.2	6.5	10	0.5-1.5 mm <sup>2</sup> 22-16 AWG	Red	25pcs
T2010C302	6.4	9.5	6.5	10	0.5-1.5 mm <sup>2</sup> 22-16 AWG	Red	25pcs
T2010C303	3.2	6.0	6.5	11	1.5-2.5 mm <sup>2</sup> 16-14 AWG	Blue	25pcs
T2010C304	3.7	6.0	6.5	11	1.5-2.5 mm <sup>2</sup> 16-14 AWG	Blue	25pcs
T2010C305	4.3	8.1	6.5	11	1.5-2.5 mm <sup>2</sup> 16-14 AWG	Blue	25pcs
T2010C306	6.4	9.3	6.5	11	1.5-2.5 mm <sup>2</sup> 16-14 AWG	Blue	25pcs
T2010C308	3.7	8.3	7.0	13	4.0-6.0 mm <sup>2</sup> 12-10 AWG	Yellow	15pcs
T2010C309	4.3	8.3	7.0	13	4.0-6.0 mm <sup>2</sup> 12-10 AWG	Yellow	15pcs
T2010C310	6.4	12.0	12.0	13	4.0-6.0 mm <sup>2</sup> 12-10 AWG	Yellow	15pcs