


Data Sheet

Receptacles (standard) No. of rows: 1 Pins per row: 20

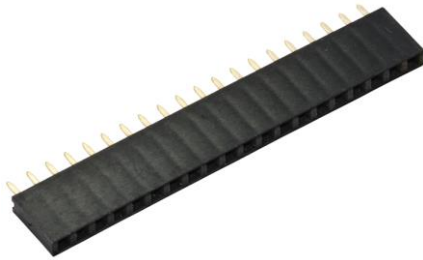

Technical data

Connector: Socket strip, straight

Contact spacing: 2.54 MM

Total number of pins: 20

Nominal current: 3A

Contact material: Brass

Pin diameter: 0.70 MM

Pin length (PCB): 2.80 MM

Socket depth : 4.2 MM

Dim (L x W x H): 50.8 x 8.5 x 2.5 MM

Operating Temperature: -40°C to 105°C