



CGS | CGS RH73

TE Internal #: 1625862-4

CGS RH73, Surface Mount Resistors, High Value/High Voltage Resistor, 2 Termination, 0805, Taped & Reeled, 30 %, Thick Film, Resistance Class 1GΩ & Up

[View on TE.com >](#)

Passive Components > Resistors > Surface Mount Resistors



Resistor Type: **High Value/High Voltage Resistor**

Number of Terminations: **2**

Package Size Code: **0805**

Packaging Method: **Taped & Reeled**

Passive Component Tolerance: **30 %**

Features

Product Type Features

Product Type	Fixed Resistor
Resistor Type	High Value/High Voltage Resistor
Package Size Code	0805
Element Type	Thick Film

Configuration Features

Number of Resistors	1
---------------------	---

Electrical Characteristics

Voltage Rating	100 V
Passive Component Tolerance	30 %
Resistance Class	1GΩ & Up
Resistance Value	50G Ω
Power Rating	.125 W

Termination Features

Number of Terminations	2
Surface Mount Resistor Termination Type	Solder

Dimensions

Passive Component Dimensions	2 x 1.2 x .4 mm
------------------------------	-----------------

Usage Conditions



Temperature Coefficient	±1000 ppm/°C
-------------------------	--------------

Packaging Features

Packaging Method	Taped & Reeled
------------------	----------------

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Reflow solder capable to 260°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

 <p>TE Part # 1625856-2 RH73 2A 100M 10% 100PPM</p>	 <p>TE Part # 1625861-3 RH73 2A 1G 30% 500PPM</p>	 <p>TE Part # 1625862-1 RH73 2A 10G 30% 1000PPM</p>	 <p>TE Part # 1625856-8 RH73 2A 50M 10% 100PPM</p>
--	--	--	---



TE Part # 1625856-4
RH73 2A 20M 10% 100PPM



TE Part # 1622818-1
RH73 2A 10M 5% 250PPM



TE Part # 1625861-5
RH73 2A 500M 30% 500PPM



TE Part # 1625856-3
RH73 2A 15M 10% 100PPM



TE Part # 1625856-5
RH73 2A 30M 10% 100PPM



TE Part # 1625856-6
RH73 2A 40M 10% 100PPM



TE Part # 1622818-2
RH73 2A 2M2 5% 250PPM



TE Part # 1622818-3
RH73 2A 4M7 5% 250PPM



TE Part # 1625861-6
RH73 2A 5G 30% 500PPM



TE Part # 1625857-3
RH73 2B 15M 20% 100PPM



TE Part # 1625857-5
RH73 2B 30M 20% 100PPM



TE Part # 1625861-9
RH73 2A 50M 20% 500PPM



TE Part # 1625862-2
RH73 2A 20G 30% 1000PPM



TE Part # 1625855-2
RH73 1J 100M 5% 100PPM




TE Part # 1625856-7
RH73 2A 50M 5% 100PPM




TE Part # 1625857-4
RH73 2B 50M 20% 100PPM

Also in the Series | CGS RH73



Surface Mount Resistors(32)

Customers Also Bought

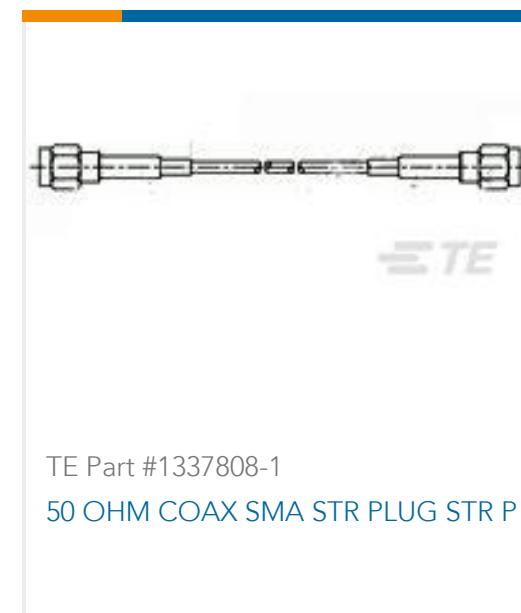

Documents

CAD Files

3D PDF

3D

Customer View Model

[ENG_CVM_CVM_1625862-4_BA.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1625862-4_BA.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1625862-4_BA.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[1309350_PASSIVE_COMPONENT](#)

English

[SMD High Value Resistors - Type RH73 Series - Tyco Electronics Passives](#)

English

RH73X2A50GNTN

CGS RH73, Surface Mount Resistors, High Value/High Voltage Resistor, 2 Termination, 0805, Taped & Reeled, 30 %, Thick Film, Resistance Class 1GΩ & Up

