

RES KIT 1206RS ✓ ACTIVE

Neohm | Neohm CRG

TE Internal #: 1625873-6

Neohm CRG, Surface Mount Resistors, General Purpose Resistor, 1206, Folder, 5 %, SMD Thick Film Resistor Kit, Thick Film, .25 W

[View on TE.com >](#)



Passive Components > Resistors > Surface Mount Resistors



Resistor Type: **General Purpose Resistor**

Package Size Code: **1206**

Packaging Method: **Folder**

Passive Component Tolerance: **5 %**

Passive Component Accessory Type: **SMD Thick Film Resistor Kit**

Features

Product Type Features

Product Type	Fixed Resistor
Resistor Type	General Purpose Resistor
Package Size Code	1206
Passive Component Accessory Type	SMD Thick Film Resistor Kit
Element Type	Thick Film

Electrical Characteristics

Passive Component Tolerance	5 %
Power Rating	.25 W

Termination Features

Surface Mount Resistor Termination Type	Solder
---	--------

Dimensions

Passive Component Dimensions	1 x .5 x .35 mm
------------------------------	-----------------

Usage Conditions

Temperature Coefficient	±100 ppm/°C
-------------------------	-------------

Packaging Features

Packaging Method	Folder
------------------	--------

Product Compliance


[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JUN 2020 (209) SVHC > Threshold: Not Yet Reviewed
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Reflow solder capable to 260°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

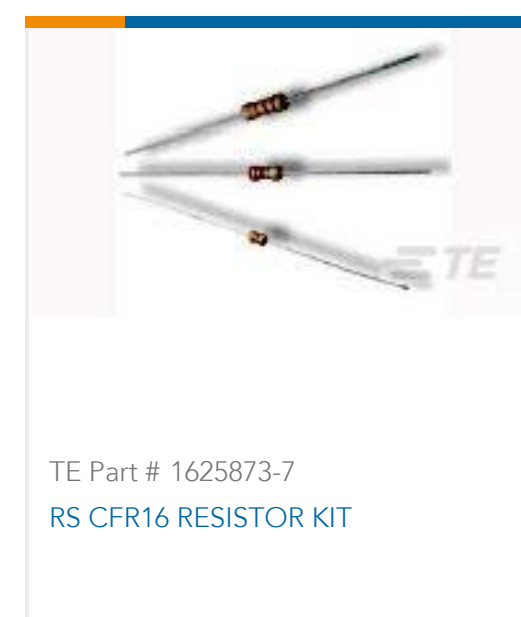



TE Part # 1-1625873-6
3521 10R-1M0 LAB KIT



TE Part # 1625873-4
0805 RESISTOR KITS




TE Part # 1-1625873-2
RS LR2 RESISTOR KIT

Also in the Series | Neohm CRG



Surface Mount Resistors(647)

Customers Also Bought

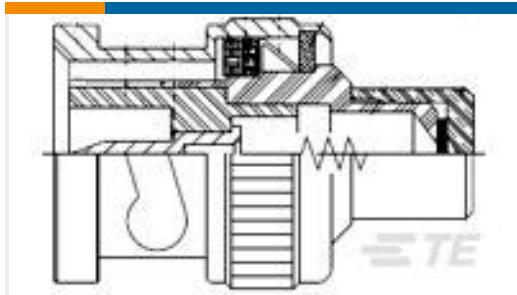

TE Part #1-1337463-0
BNC Plg Term 50Ohm Silver Pltd



TE Part #1-1624110-3
3650 1008 LAB KIT




TE Part #1-1825137-1
A103SDCQ04



TE Part #1-1623927-9
CFR16 5% 180R



TE Part #1-2176163-7
UPF50 0.1% 5PPM 50R

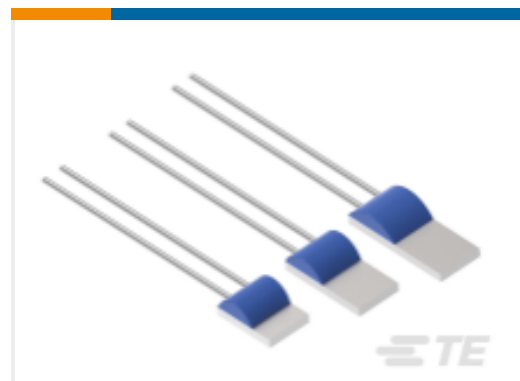

TE Part #NB-PTCO-160
RTD Platinum Thin Film Element




TE Part #1-1478966-0
SMA B/HD SKT RCPT GSS



TE Part #1-1625873-1
RS LR1 RESISTOR KIT



TE Part #1-2176374-5
RQ 0805 150R 0.1% 10PPM 1K RL

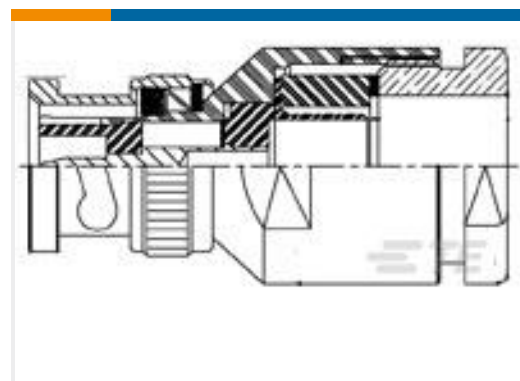

TE Part #1-1478402-0
BNC Str Plg PS 50Ohm Silver RG174A /U, 18



Documents

Product Drawings

[RS 1206 RESISTOR KIT](#)

English

Datasheets & Catalog Pages

[1309350_PASSIVE_COMPONENT](#)

English

[Thick Film Chip Resistors - Type CRG series](#)

English