

1825622-1 ✓ ACTIVE

[Alcoswitch](#) | [Alcoswitch FCR](#)

TE Internal #: 1825622-1

Alcoswitch FCR, Switch Boots & Accessories, Knurled Nut, Miniature Toggle Switches, Round Style, Silver

[View on TE.com >](#)



Relays, Contactors & Switches > Switches > Hardware & Seals



Switch Boot Accessory Type: **Knurled Nut**

Switch Boot & Accessory For Use With: **Miniature Toggle Switches**

Style: **Round**

Switch Boot & Accessory Color: **Silver**

Features

Product Type Features

Product Type	Accessory
Switch Boot Accessory Type	Knurled Nut
Style	Round

Configuration Features

End Mounting Plates (Pair)	Decorative
----------------------------	------------

Body Features

Finish	Bright Nickel
Switch Boot & Accessory Color	Silver

Mechanical Attachment

Screw & Hole Thread Size	1/4 – 40
--------------------------	----------

Operation/Application

Switch Boot & Accessory For Use With	Miniature Toggle Switches
--------------------------------------	---------------------------

Packaging Features

Packaging Method	Bag/Box
------------------	---------

Other

Comment	Decorative for ultimate appearance.
---------	-------------------------------------

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)



EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	<p>Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JUN 2018 (191) SVHC > Threshold: Pb (3.7% in Component Part)</p> <p>Article Safe Usage Statements: Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.</p>
Halogen Content	Not Yet Reviewed for halogen content
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts




Also in the Series | [Alcoswitch FCR](#)



Switch Boots & Accessories(15)


Customers Also Bought

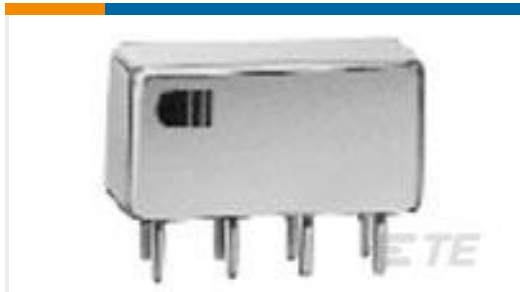


TE Part #2-1617031-1
HFW1201K45M = M39016/6-109M



TE Part #3-1393250-0
W28-XQ1A-15=W28-

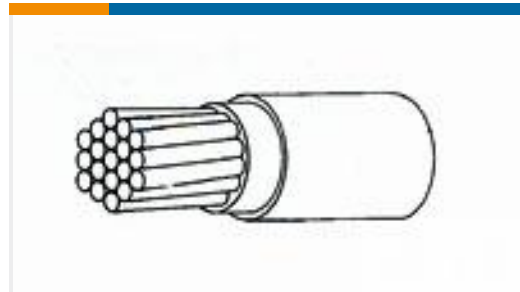

TE Part #218204-001
22759/34-20-9

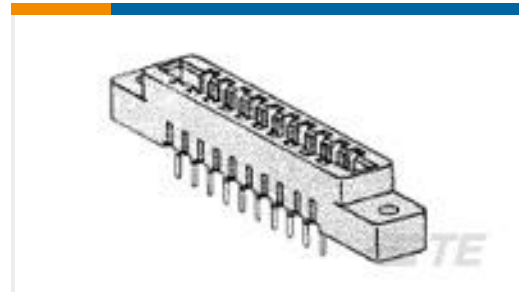

TE Part #2-530654-2
CONN LOW PRO 10 POS 156SOL-EYE



TE Part #1676393-3
RN 0805 60K4 0.1% 10PPM 5KRL



TE Part #1437628-7
N1-AG=NUT1/4-40 KNURLED



TE Part #YDTS20T19-32SAV001
D38999: Square Flange, 19-32 insert



TE Part #350690-3
UMNL PIN 24-18 PTPPHBZ L/P



TE Part #193839-3
SKT HEADER, RIGHT ANGLE



TE Part #1676343-3
RN 0805 44K2 0.1% 10PPM 5KRL

Documents

Product Drawings

[N1A04=Nut Decorative](#)

English

Datasheets & Catalog Pages

[SWITCHES_CORE_PROGRAM_CATALOG](#)

English