

RN73C1E4K87BTDF

✓ ACTIVE

Holsworthy | Holsworthy RN73

TE Internal #: 7-1879130-7

Holsworthy RN73, Surface Mount Resistors, Precision Resistor, 2 Termination, 0402, Taped & Reeled, .1 %, Thin Film, Resistance Class 1kΩ – 1MΩ, 4.87K Ω

[View on TE.com >](#)



Passive Components > Resistors > Surface Mount Resistors



Resistor Type: **Precision Resistor**  
Number of Terminations: **2**  
Package Size Code: **0402**  
Packaging Method: **Taped & Reeled**  
Passive Component Tolerance: **.1 %**

Features

Product Type Features

|                   |                    |
|-------------------|--------------------|
| Product Type      | Fixed Resistor     |
| Resistor Type     | Precision Resistor |
| Package Size Code | 0402               |
| Element Type      | Thin Film          |

Configuration Features

|                     |   |
|---------------------|---|
| Number of Resistors | 1 |
|---------------------|---|

Electrical Characteristics

|                             |           |
|-----------------------------|-----------|
| Voltage Rating              | 25 V      |
| Passive Component Tolerance | .1 %      |
| Resistance Class            | 1kΩ – 1MΩ |
| Resistance Value            | 4.87K Ω   |
| Power Rating                | .063 W    |

Termination Features

|                                         |        |
|-----------------------------------------|--------|
| Number of Terminations                  | 2      |
| Surface Mount Resistor Termination Type | Solder |

Dimensions

|                              |                |
|------------------------------|----------------|
| Passive Component Dimensions | 1 x .5 x .3 mm |
|------------------------------|----------------|



Usage Conditions

|                         |            |
|-------------------------|------------|
| Temperature Coefficient | ±10 ppm/°C |
|-------------------------|------------|

Packaging Features

|                  |                |
|------------------|----------------|
| Packaging Method | Taped & Reeled |
|------------------|----------------|

Product Compliance

For compliance documentation, visit the product page on TE.com>

|                                               |                                                                                                                                         |
|-----------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------|
| EU RoHS Directive 2011/65/EU                  | Compliant                                                                                                                               |
| EU ELV Directive 2000/53/EC                   | Compliant                                                                                                                               |
| China RoHS 2 Directive MIIT Order No 32, 2016 | No Restricted Materials Above Threshold                                                                                                 |
| EU REACH Regulation (EC) No. 1907/2006        | Current ECHA Candidate List: JAN 2021 (211)<br>Candidate List Declared Against: JUN 2020 (209)<br>SVHC > Threshold:<br>Not Yet Reviewed |
| Halogen Content                               | Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free                                                     |
| Solder Process Capability                     | Reflow solder capable to 260°C                                                                                                          |

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts






TE Part # 1614349-9  
RN 0603 10K 0.1% 10PPM CUT LENGTH




TE Part # 1676153-3  
RN 0805 10K 0.1% 10PPM 5KRL



TE Part # 1676153-2  
RN 0805 10K 0.1% 10PPM 1KRL

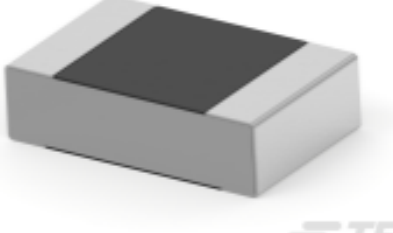


TE Part # 1-1676142-3  
RN 0805 100K 0.01% 10PPM 5K RL

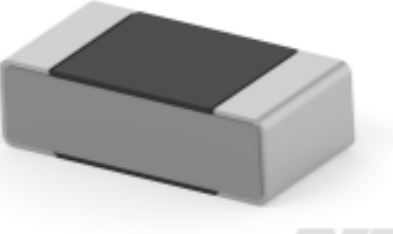


TE Part # 8-1879130-4  
RN 0402 5K11 0.1% 10PPM 5K RL

Also in the Series | [Holsworthy RN73](#)

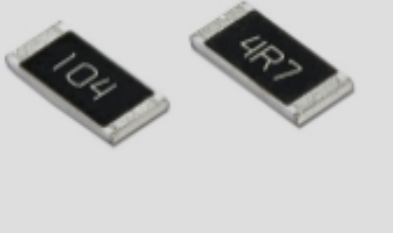

[Surface Mount Resistors\(2573\)](#)


Customers Also Bought

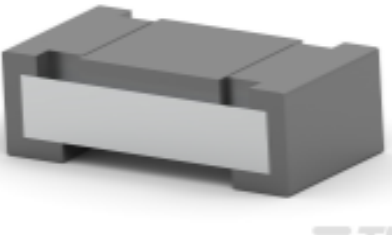

TE Part #1-2176053-0  
Thick Film Resistor: Current Sense



TE Part #1-1879208-7  
CPF 0402 47R 0.1% 25PPM 1K RL

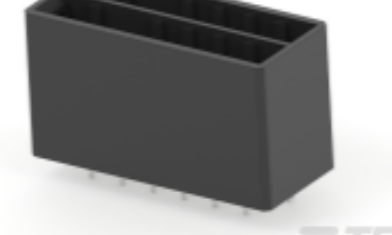


TE Part #1-179277-2  
DYNAMIC 3200 HDR ASSY



TE Part #1-1871468-2  
DYNAMIC 1200 HDR ASSY




TE Part #T4144015041-000  
M12 Panel Mount PCB

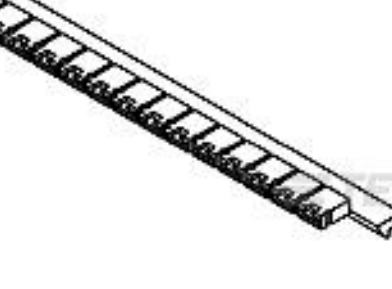

TE Part #142270-3  
CONNECTOR SHUNT 2 P



TE Part #1393803-8  
V23100V6003A112

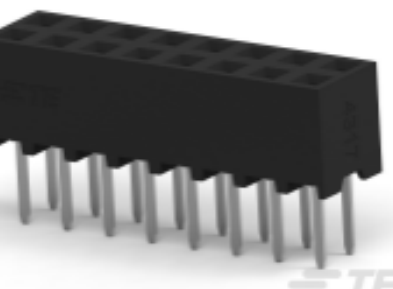

TE Part #1-2314826-6  
16P,2MM,B-B,REC,DRVT,2.7,0.76AU, TB,W/CAP

RN73C1E4K87BTDF

Holsworthy RN73, Surface Mount Resistors, Precision Resistor, 2 Termination, 0402, Taped & Reeled, .1 %, Thin Film, Resistance Class 1kΩ – 1MΩ, 4.87K Ω



TE Part #1-2319747-5  
TRI-STATE DIP 10P G RECESS SEAL  
TUBE



TE Part #1413009-9  
V23086C2001A403

Documents

Product Drawings

RN 0402 4K87 0.1% 10PPM 1K RL

English

CAD Files

3D PDF

3D

Customer View Model

ENG\_CVM\_CVM\_7-1879130-7\_BA.2d\_dxf.zip

English

Customer View Model

ENG\_CVM\_CVM\_7-1879130-7\_BA.3d\_igs.zip

English

Customer View Model

ENG\_CVM\_CVM\_7-1879130-7\_BA.3d\_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

1309350\_PASSIVE\_COMPONENT

English

High Precision Resistors (SMD) - Type RN73 Series - Tyco Electronics Passives

English

8-1773459-4\_POWER\_FILTERING\_AND\_RESISTIVE\_SOLUTIONS\_FOR\_ELEVATORS\_AND\_ESCALATORS

English