

RN73C1J84K5BTDF

✓ ACTIVE

Holsworthy | Holsworthy RN73

TE Internal #: 9-1879134-1

Holsworthy RN73, Surface Mount Resistors, Precision Resistor, 2 Termination, 0603, Taped & Reeled, .1 %, Thin Film, Resistance Class 1kΩ – 1MΩ, 84.5K Ω

[View on TE.com >](#)



Passive Components > Resistors > Surface Mount Resistors



Resistor Type: **Precision Resistor**  
Number of Terminations: **2**  
Package Size Code: **0603**  
Packaging Method: **Taped & Reeled**  
Passive Component Tolerance: **.1 %**

Features

Product Type Features

|                   |                    |
|-------------------|--------------------|
| Product Type      | Fixed Resistor     |
| Resistor Type     | Precision Resistor |
| Package Size Code | 0603               |
| Element Type      | Thin Film          |

Configuration Features

|                     |   |
|---------------------|---|
| Number of Resistors | 1 |
|---------------------|---|

Electrical Characteristics

|                             |           |
|-----------------------------|-----------|
| Voltage Rating              | 50 V      |
| Passive Component Tolerance | .1 %      |
| Resistance Class            | 1kΩ – 1MΩ |
| Resistance Value            | 84.5K Ω   |
| Power Rating                | .063 W    |

Termination Features

|                                         |        |
|-----------------------------------------|--------|
| Number of Terminations                  | 2      |
| Surface Mount Resistor Termination Type | Solder |

Dimensions

|                              |                    |
|------------------------------|--------------------|
| Passive Component Dimensions | 1.55 x .8 x .45 mm |
|------------------------------|--------------------|



Usage Conditions

|                         |            |
|-------------------------|------------|
| Temperature Coefficient | ±10 ppm/°C |
|-------------------------|------------|

Packaging Features

|                  |                |
|------------------|----------------|
| Packaging Method | Taped & Reeled |
|------------------|----------------|

Product Compliance

For compliance documentation, visit the product page on TE.com>

|                                               |                                                                                                                               |
|-----------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------|
| EU RoHS Directive 2011/65/EU                  | Compliant                                                                                                                     |
| EU ELV Directive 2000/53/EC                   | Compliant                                                                                                                     |
| China RoHS 2 Directive MIIT Order No 32, 2016 | No Restricted Materials Above Threshold                                                                                       |
| EU REACH Regulation (EC) No. 1907/2006        | Current ECHA Candidate List: JAN 2021 (211)<br>Candidate List Declared Against: JAN 2021 (211)<br>Does not contain REACH SVHC |
| Halogen Content                               | Not Low Halogen - contains Br or Cl > 900 ppm.                                                                                |
| Solder Process Capability                     | Reflow solder capable to 260°C                                                                                                |

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts




TE Part # 1614349-9  
RN 0603 10K 0.1% 10PPM CUT LENGTH



TE Part # 1676153-3  
RN 0805 10K 0.1% 10PPM 5KRL



TE Part # 1676153-2  
RN 0805 10K 0.1% 10PPM 1KRL

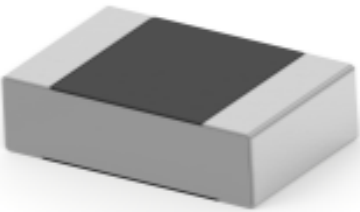

TE Part # 1-1676142-3  
RN 0805 100K 0.01% 10PPM 5K RL

RN73C1J84K5BTDF

Holsworthy RN73, Surface Mount Resistors, Precision Resistor, 2 Termination, 0603, Taped & Reeled, .1 %, Thin Film, Resistance Class 1kΩ – 1MΩ, 84.5K Ω



TE Part # 8-1879130-4

RN 0402 5K11 0.1% 10PPM 5K RL

Also in the Series | Holsworthy RN73

Surface Mount Resistors(2573)

Customers Also Bought

TE Part #1825965-1

FSMH=3.5 X 6.0 X 5.0 TACT SWITCH, HT

TE Part #1-1879225-8

CPF 0603 59K 0.1% 25PPM 1K RL

TE Part #1-2176216-9

CPF A 0603 330R 0.1% 25PPM 1K RL

TE Part #1622350-1

LR1 1% 1K1

TE Part #1879623-3

H4 15K 0.05% 15PPM

TE Part #1879623-5

H4 6K98 0.05% 15PPM

TE Part #T4144015041-000

M12 Panel Mount PCB

TE Part #1-2314826-6

16P,2MM,B-B,REC,DRV,T,2.7,0.76AU, TB,W/CAP

TE Part #1623963-1

SC10-10-0547-10 680UH AMMO 1000

TE Part #1-2319747-5

TRI-STATE DIP 10P G RECESS SEAL TUBE





Documents

CAD Files

3D PDF

3D

Customer View Model

ENG\_CVM\_CVM\_9-1879134-1\_BA.2d\_dxf.zip

English

Customer View Model

ENG\_CVM\_CVM\_9-1879134-1\_BA.3d\_igs.zip

English

Customer View Model

ENG\_CVM\_CVM\_9-1879134-1\_BA.3d\_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

1309350\_PASSIVE\_COMPONENT

English

High Precision Resistors (SMD) - Type RN73 Series - Tyco Electronics Passives

English

8-1773459-4\_POWER\_FILTERING\_AND\_RESISTIVE\_SOLUTIONS\_FOR\_ELEVATORS\_AND\_ESCALATORS

English