



Product Compliance

For compliance documentation, visit the product page on TE.com>


EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2018 (181) SVHC > Threshold: Not Yet Reviewed
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Customers Also Bought




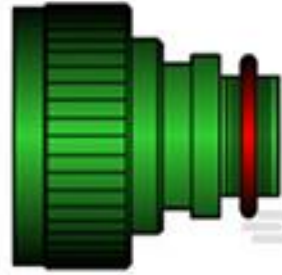

TE Part #661269-000
TXR21AB00-1605AI



TE Part #1617807-5
FC-335-SY8= RELAY, 3PST

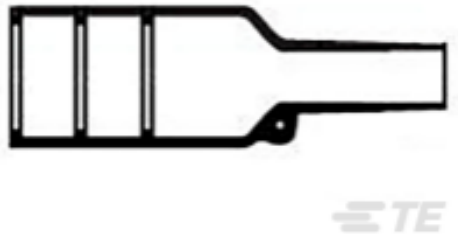

TE Part #358203-000
Bulbous Heat Shrink Boots: Lipped, Straight



TE Part #2-1614894-3
CPF 0805 301K 0.1% 25PPM 1K RL



TE Part #642427-000
Heat Shrink Boots: Poly Mold, Lipped



TE Part #1617147-5
JMGAP-26P = M39016/17-030P



TE Part #1617164-7
JMACT-5XL = M28776/1-025L

TE Part #358279-000
382C312-50-01-0



TE Part #ZPF000000000007174
983-ORS 08-98 PN



TE Part #1617119-5
J1MAW-18XP = M39016/7-021P

Documents

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_2173752-2_B.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_2173752-2_B.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_2173752-2_B.3d_stp.zip

English

By downloading the CAD file I accept and agree to the Terms and Conditions of use.

Product Specifications

Product Specification

English

Product Environmental Compliance



TE Material Declaration

English