




Connectors > D-Shaped Connectors > D-Sub Accessories > Locking & Mounting

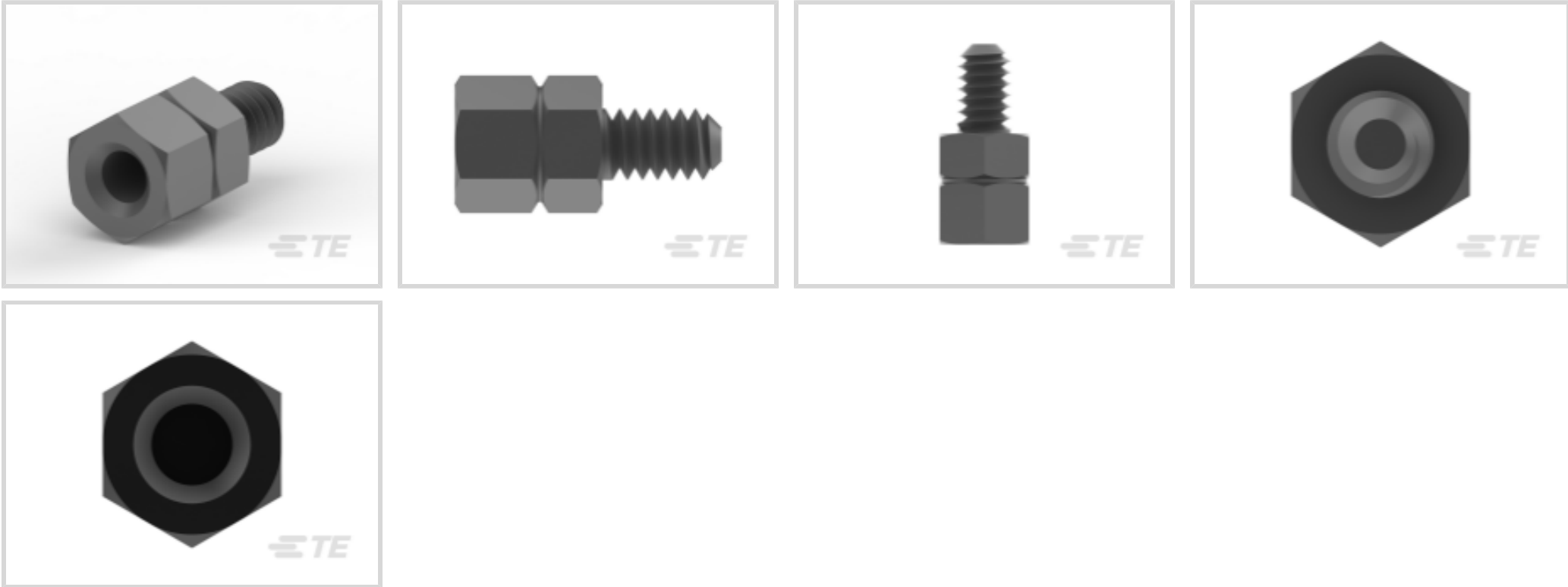

D-Shaped Connector Accessories: **Female Screwlocks**

Screw Length: **11.2 mm [.44 in]**

Features

Product Type Features

Product Type	Accessory
D-Shaped Connector Accessories	Female Screwlocks

Mechanical Attachment

Screwlock Style	Screwlock Only
Mating Thread Size	14702
Screw & Hole Thread Size	4-40 UNC
Screw Length	11.2 mm[.44 in]

Dimensions

Thread Length	5 mm[.197 in]
---------------	---------------

Packaging Features

Packaging Quantity	2000
Packaging Method	Carton

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
------------------------------	---------------------------



EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) SVHC > Threshold: Pb (3.5% in Component Part) Article Safe Usage Statements: Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



Also in the Series | [AMPLIMITE Kit](#)

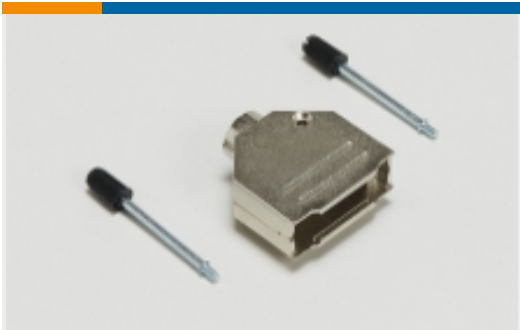

D-Sub Backshells & Clamps(136)



D-Sub Contact Accessories(1)




D-Sub Covers(3)



D-Sub Locking & Mounting(122)

Customers Also Bought

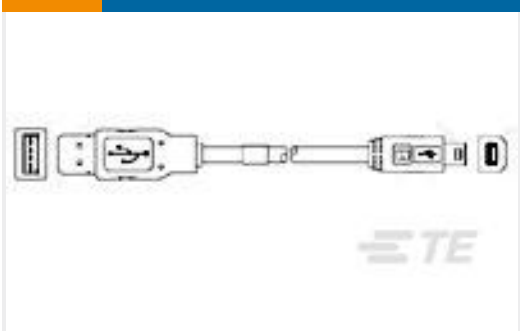

TE Part #1487588-2
USB, A-B, 28/24, WHITE, 1.5M



TE Part #1-1879208-7
CPF 0402 47R 0.1% 25PPM 1K RL



TE Part #1-828102-1
HD-20SCHRAUB-SICHRG



TE Part #1-826470-0
2X10P MOD II SHROUDED HEADER, RT ANG.



TE Part #1-1825096-4
TPA21CCGRA004



TE Part #1-826470-3
2X13P MOD II SHROUDED HEADER, RT ANG.



TE Part #1-1478966-0
SMA B/HD SKT RCPT GSS



TE Part #1218125-4
37 POS,ASSY,PLUG,LOW PROF,109



TE Part #928205-6
6P TELFIX BU-GEH



TE Part #1-963181-1
56P MESSERLEIST KPL

Documents

Product Drawings
HD-20SCHRAUB-SICHRG

English

CAD Files
3D PDF
3D
Customer View Model
ENG_CVM_CVM_828102-1_J.2d_dxf.zip



English

Customer View Model

[ENG_CVM_CVM_828102-1_J.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_828102-1_J.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Environmental Compliance

[TE Material Declaration](#)

English