




Connectors > Rectangular Connectors > Rectangular Connector Accessories > Rectangular Connector Adapters

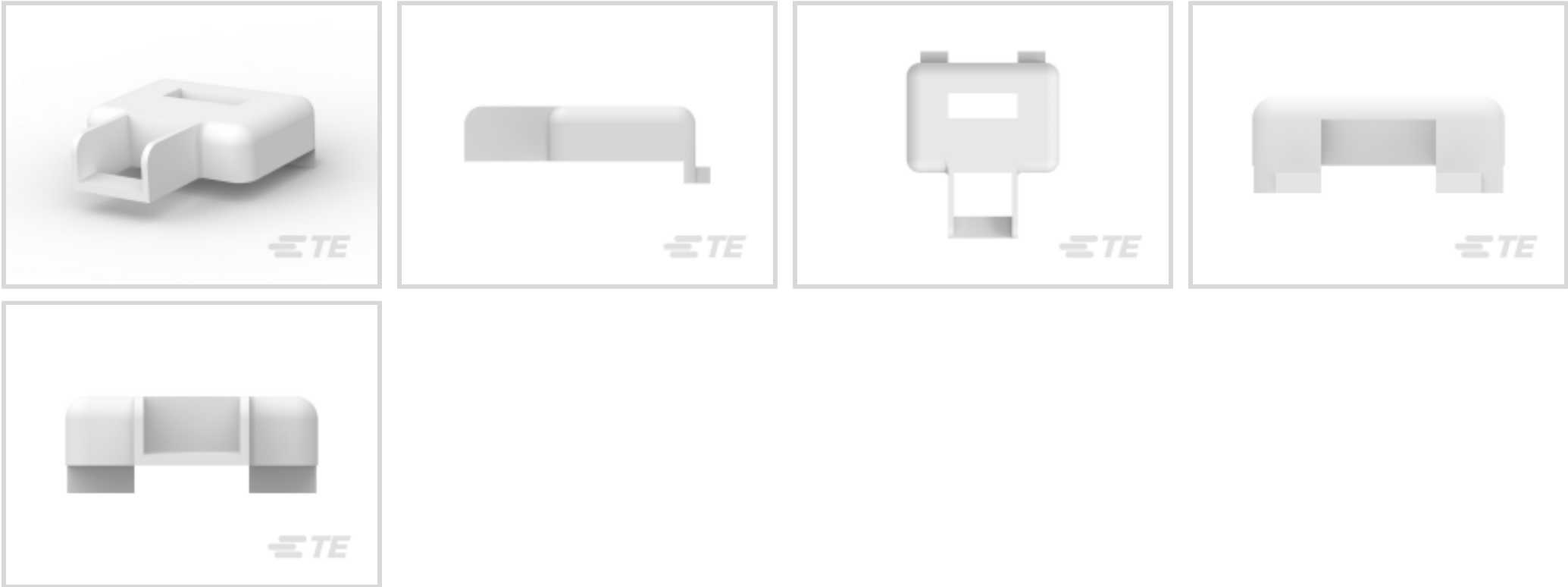

Rectangular Connector Adapter Type: **Cap Housing Adapter**

Agency/Standard: **CSA, UL, VDE**

Operating Voltage: **600 VAC**

UL Flammability Rating: **UL 94V-2**

Features

Product Type Features

Rectangular Connector Adapter Type	Cap Housing Adapter
------------------------------------	---------------------

Electrical Characteristics

Operating Voltage	600 VAC
-------------------	---------

Body Features

Color	Natural
Material	Nylon

Housing Features

Housing Material	Glass-Filled Nylon
------------------	--------------------

Industry Standards

Agency/Standard	CSA, UL, VDE
UL Flammability Rating	UL 94V-2

Packaging Features

Packaging Quantity	500
Packaging Method	Bag



Other

Comment	"For all positions except 2, 6 and 8 position cap housings.", With NIBS.
---------	--

Product Compliance


For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

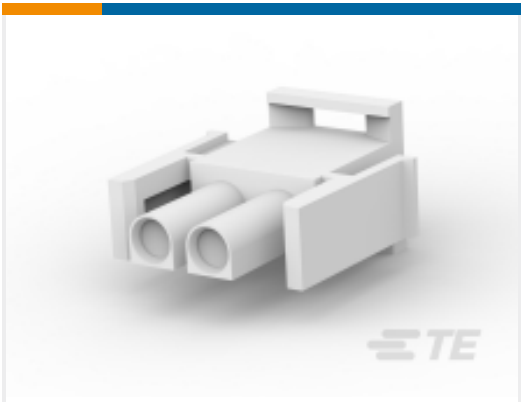 TE Part # 643182-2 UMNL STR/REL ADAPTER CAP	 TE Part # 350848-2 02P UMNL PLUG TEST ASSY 94VO	 TE Part # 643182-1 UMNL STR/REL ADAPTER CAP NATL	 TE Part # 1-640415-1 UMNL KEYING PLUG V2 NATL
--	---	---	--



TE Part # 1586099-1
06P UMNL WIRE SEAL GRAY 12AWG

TE Part # 641778-1
UMNL STR/REL ADAPTER

TE Part # 641778-2
UMNL STR/REL ADAPTER *NO NIBS*

TE Part # 350848-3
03P UMNL PLUG TEST ASSY 94VO

TE Part # 641777-2
UMNL STR/REL ADAPTER *NO NIBS*

TE Part # 643131-2
UMNL STR/REL ADAPTER CAP

Also in the Series | Universal MATE-N-LOK

Circular Power Connectors(2)

Connector Contacts(11)

Insertion & Extraction Tools(4)

Power Contacts(207)

Rectangular Boots & Strain Relief(35)

Rectangular Connector Adapters(7)

Rectangular Connector Housings(2)

Rectangular Connector Keying Plugs(3)

Rectangular Connector Locking(4)

Rectangular Connector Seals(26)

Rectangular Power Connectors(725)


Customers Also Bought



TE Part #1-745491-8
IDC D-Sub: Receptacle Assembly,
Wire to Wire, Signal, 2.74 mm



TE Part #1-640550-1
Polyester PCB Connector Covers: 2.54
mm, MTA 100

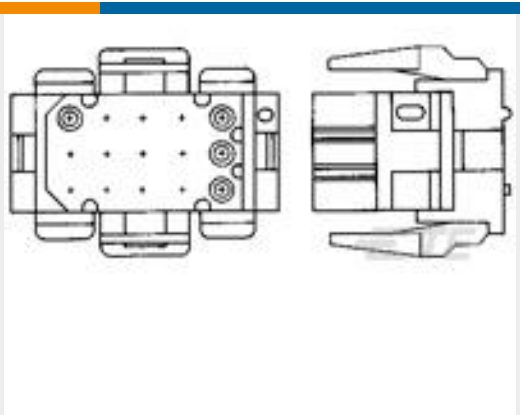

TE Part #1-640523-0
15P MR II PLUG HSG V0 RED



TE Part #1-770901-0
MINI UMNL PIN 26-22 AWG AU LF



TE Part #1-480703-1
04P UMNL CAP HSG BRN



TE Part #9-1419111-4
PT571048



TE Part #1-640724-0
15P UMNL STR/REL & INSRT NATL



TE Part #1-640723-0
12P UMNL STR/REL & INSRT NATL



TE Part #1-640721-0
06P UMNL STR/REL & INSRT NATL



TE Part #1-640719-0
02P UMNL STR/REL & INSRT NATL

Documents

Product Drawings

UMNL STR/REL ADAPTER NATL

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_641777-1_F2.3d_igs.zip

English

Customer View Model

ENG_CVM_641777-1_F2.3d_stp.zip

English

Customer View Model

ENG_CVM_641777-1_F2.2d_dxf.zip

English

3D PDF

English



Customer View Model

[ENG_CVM_CVM_641777-1_N.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_641777-1_N.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_641777-1_N.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[SOFT_SHELL_PIN_SOCKET_CONNECTORS_STANDARD_DENSITY](#)

English

Product Environmental Compliance

[TE Material Declaration](#)

English

Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English