

1-2306128-1 ✓ ACTIVE

LUMAWISE | LUMAWISE Endurance N

TE Internal #: 1-2306128-1

LUMAWISE Endurance N, ANSI Street Lighting Accessories, Cover, Natural, Product Diameter 3 in [76 mm], Sleeve Compatible / Not Vented, Sealable

[View on TE.com >](#)



Connectors > Lighting Connectors > Street Lighting Controls > ANSI Street Lighting Accessories > PHOTO CONTROL COVER



Lighting Product Type: **Cover**

Primary Product Color: **Natural**

Product Diameter: **76 mm [3 in]**

Lighting Connector Features Included: **Not Vented, Sleeve Compatible**

Sealable: **Yes**

[All PHOTO CONTROL COVER \(10\)](#)

Features

Product Type Features

Lighting Product Type	Cover
Sealable	Yes

Configuration Features

Lighting Connector Features Included	Not Vented, Sleeve Compatible
--------------------------------------	-------------------------------

Body Features

Primary Product Color	Natural
-----------------------	---------

Dimensions

Product Diameter	76 mm[3 in]
------------------	-------------

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
------------------------------	-----------









EU ELV Directive 2000/53/EC	Not Yet Reviewed
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JUN 2020 (209) SVHC > Threshold: Not Yet Reviewed
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

 <p>TE Part # CAT-ST833-P5663A PHOTO CONTROL BASE</p>	 <p>TE Part # 1-2336396-1 ASSEMBLY, LIGHT CONTROLLER BASE, W/VENT</p>	 <p>TE Part # 2336396-1 ASSEMBLY, LIGHT CONTROLLER BASE, W/VENT</p>	 <p>TE Part # 1-2213871-3 LIGHT CONTROLLER BASE ASSY, 76MM DIA,3POS</p>
 <p>TE Part # 1-2325661-1 LUMAWISE ENDURANCE N SHRTG CAP BASE VENT</p>	 <p>TE Part # 2325661-1 LUMAWISE ENDURANCE N SHRTNG CAP BASE ASM</p>		

Also in the Series | LUMAWISE Endurance N




ANSI Street Lighting Accessories(17)



ANSI Street Lighting Base Assemblies (14)



ANSI Street Lighting Power Management(6)

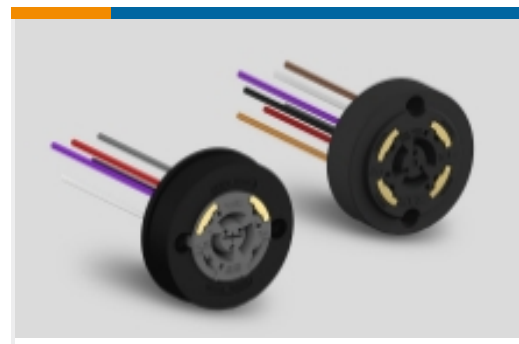

ANSI Street Lighting Receptacles(25)



Street Lighting Open & Shorting Caps (3)

Customers Also Bought



TE Part #1-2213871-1
PHOTO CONTROL BASE



TE Part #1-2315539-1
PHOTO CONTROL COVER



TE Part #1-2328823-1
LUMAWISE Endurance S Domes



TE Part #1-1393243-1
RTE24048




TE Part #1-2336396-2
ASSEMBLY, LIGHT CONTROLLER BASE, W/VENT



TE Part #2-1879640-0
H4P 2K87 0.5% 50PPM




TE Part #A27037-000
PVF SELF LAMINATING PVF LABELS

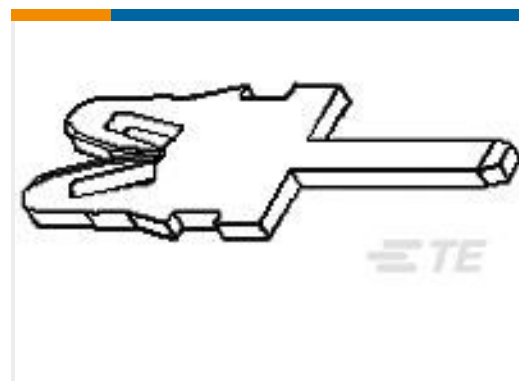

TE Part #1601138-1
151-005-000=TAB,3.3X0.8,MEDSMZ



TE Part #1-2316102-2
12P,2MM,REC,HSG,SR,CRIMP,PLAIN, BOX

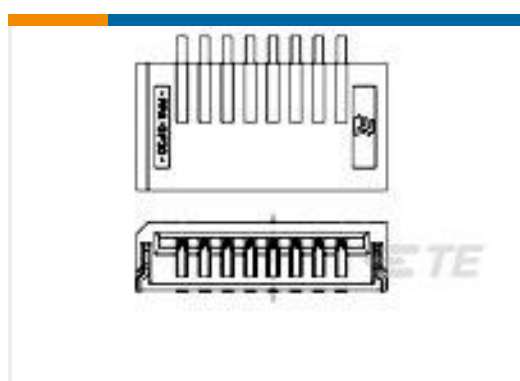

TE Part #1735360-8
1mm FFC SMT H BOTTOM CONTACT ASSY, 8P

Documents



Product Drawings

[COVER, LIGHT CONTROLLER, 76MM DIA,SHORT](#)

English

CAD Files

[3D PDF](#)

3D

Customer View Model

[ENG_CVM_CVM_1-2306128-1_A.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1-2306128-1_A.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1-2306128-1_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[LUMAWISE ENDURANCE N CONTROL BASE, SLEEVE AND COVER](#)

English

[LUMAWISE STREET LIGHT DIMMING AND CONTROL QUICK REFERENCE GUIDE](#)

English

[LUMAWISE ENDURANCE N CONTROL BASE, SLEEVE AND COVER](#)

Product Specifications

[Application Specification](#)

English

Agency Approvals

[Dimmable Photocontrol CB Certificate](#)

English