




Connectors > D-Shaped Connectors > D-Sub Accessories > D-Sub Backshells & Clamps

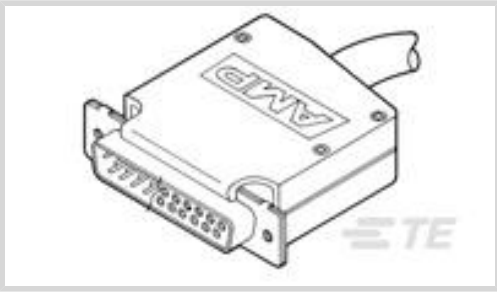

D-Shaped Connector Accessories: **Cable Clamp Kit**

Cable Clamp Type: **Clam Shell**

Compatible With Connector Shell Size: **3**

Shielded: **No**

Cable Insulation Diameter Range: **10.67 mm [.42 in]**

Features

Product Type Features

Clam Shell Length	Short
Grommets	Without
D-Shaped Connector Accessories	Cable Clamp Kit
Connector & Contact Terminates To	Wire & Cable

Body Features

Shield Plating Material	None
Cable Clamp Material	Polypropylene
Color	Black
Cable Clamp Type	Clam Shell
Cable Exit Angle	180° (In-Line), 45°

Mechanical Attachment

Screw & Hole Thread Size	6-32
--------------------------	------

Dimensions

Cable Insulation Diameter Range	10.67 mm[.42 in]
---------------------------------	------------------

Operation/Application

Compatible With Connector Shell Size	3
Shielded	No

Packaging Features

--	--



Packaging Quantity	1
Packaging Method	Bag

Other

Comment	All parts are packaged unassembled.
---------	-------------------------------------

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Not Yet Reviewed
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulations, TE’s information on SVHC in articles for this part number is still based on the European Chemical Agency (ECHA) ‘Guidance on requirements for substances in articles’(Version: 2, April 2011), applying the 0.1% weight on weight concentration threshold at the finished product level. TE is aware of the European Court of Justice ruling of September 10th, 2015 also known as O5A (Once An Article Always An Article) stating that, in case of ‘complex object’, the threshold for a SVHC must be applied to both the product as a whole and simultaneously to each of the articles forming part of its composition. TE has evaluated this ruling based on the new ECHA “Guidance on requirements for substances in articles” (June 2017, version 4.0) and will be updating its statements accordingly.

Compatible Parts



TE Part # 1-5206478-2
CABLE CLAMP ASSEMBLY,KIT



TE Part # 5205718-1
CABLE SUPPORT HSG ASSY



TE Part # 205716-1
GATE CABLE SUPPORT SIZE 3



Also in the Series

AMPLIMITE Kit



D-Sub Backshells & Clamps(136)



D-Sub Contact Accessories(1)



D-Sub Covers(3)



D-Sub Locking & Mounting(122)


Customers Also Bought



TE Part #1-644042-2
Nylon Gold Plated Receptacle: 2.54 mm, With Mating Alignment, MTA 100



TE Part #1-2007637-7
SFP+ Stacked Cage Assemblies

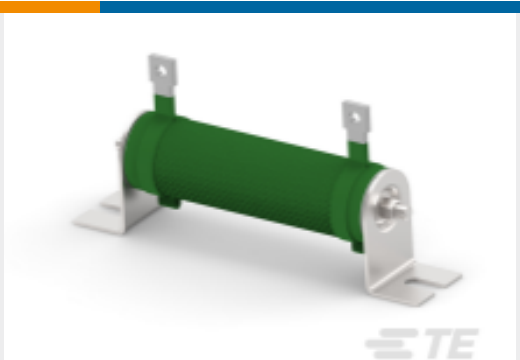

TE Part #1-1879457-2
Wirewound Resistor: Mineral, 2.5 Kw



TE Part #0660-206-1282
CONT PIN



TE Part #1-201692-1
CNTR FASTENER PLUG BLOCK,104P



 
TE Part #1-1437596-9
TRD23N10WL=ROCKER,DPDT, BLACK



TE Part #103239-5
05 MODII HDR SRST B/A .100CL



TE Part #971111-2
25W FRC MADISON SPEC 100-4703 REV. 7



TE Part #0619-5-1378
R SNAP

Documents

Product Drawings

AMPLIMITE ASSEMBLY,SIZE 3

English

CAD Files

3D PDF

3D



Customer View Model

ENG_CVM_CVM_5206390-1_O.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_5206390-1_O.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_5206390-1_O.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

AMPLIMITE Subminiature D Connectors - Cable Connectors

English

AMPLIMITE Cable Connectors and Shielding Hardware Kits QRG

English

Instruction Sheets

Instruction Sheet (U.S.)

English