



Connectors > D-Shaped Connectors > D-Sub Accessories > D-Sub Backshells & Clamps



D-Shaped Connector Accessories: **Cable Clamp Kit**

Cable Clamp Type: **Dataphone**

Number of Positions: **15**

Compatible With Connector Shell Size: **2**

Shielded: **No**

Features

Product Type Features

Grommets	Without
Product Type	Accessory
D-Shaped Connector Accessories	Cable Clamp Kit
Connector & Contact Terminates To	Wire & Cable

Configuration Features

Number of Positions	15
---------------------	----

Body Features

Shield Plating Material	None
Cable Clamp Material	Polypropylene
Color	Black
Cable Clamp Type	Dataphone
Cable Exit Angle	180° (In-Line)

Mechanical Attachment

Screw & Hole Thread Size	4-40
--------------------------	------



Dimensions

Cable Insulation Diameter Range	10.16 mm[.4 in]
---------------------------------	-----------------

Operation/Application

Compatible With Connector Shell Size	2
Shielded	No

Packaging Features

Packaging Quantity	1
Packaging Method	Bag

Other

Comment	Cable diameter is adjustable by changing cable support gates., Molded-in identification is provided on cable support gates to facilitate proper selection with regard to shell size and maximum acceptable cable diameter.
---------	--

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	BFR/CFR/PVC Free, but Br/Cl >900 ppm in other sources.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides



on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

TE Part # 5748678-2
2 PC PLST CBL CLMP KIT

Also in the Series | AMPLIMITE Kit

D-Sub Backshells & Clamps(136)

D-Sub Contact Accessories(1)

D-Sub Covers(3)

D-Sub Locking & Mounting(122)

Customers Also Bought

TE Part #207516-5
D-Sub Crimp Recpt Signal 25 Posn, Socket Size 20, Shell Size 3

TE Part #1658644-1
D-Sub Crimp Recpt Signal 15 Posn, Socket Size 20, Shell Size 2

TE Part #1658543-2
D-Sub Conn Contacts: Socket, Phosphor Bronze, Signal, Size 20


TE Part #1658544-3
D-Sub Connector Contacts: Pin, Brass, Signal, Size 20

TE Part #2-326875-4
PIDG RING TONGUE TERMINALS

TE Part #2-745495-0
IDC D-Sub: Receptacle Assembly, Wire to Wire, Signal, 2.77 mm

TE Part #1-746610-6
26 DIP PLUG, 100CL, LEAD FREE

TE Part #1-746610-5
20 DIP PLUG, 100CL, LEAD FREE

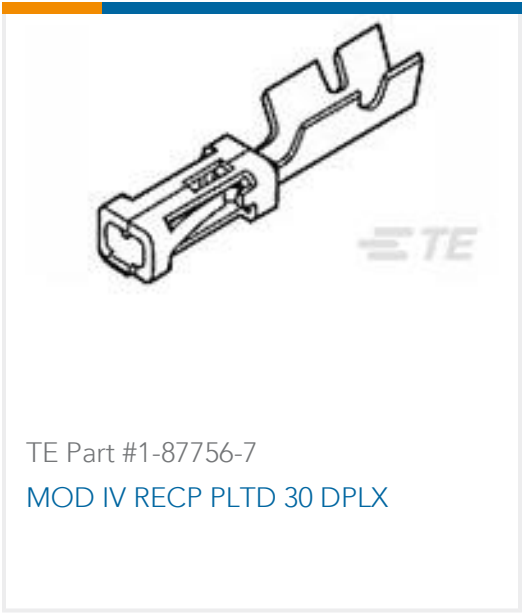

Documents

Product Drawings

STR REL ASSY 15 POS SZ 2 AMPLI

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_5745122-2_O.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_5745122-2_O.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_5745122-2_O.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

AMPLIMITE Subminiature D Connectors - Cable Connectors

English

AMPLIMITE Cable Connectors and Shielding Hardware Kits QRG

English

Product Environmental Compliance

MD_5745122-2_02272019814_dmtec

English

MD_5745122-2_02272019814_dmtec

English