




Connectors > D-Shaped Connectors > D-Sub Accessories > D-Sub Backshells & Clamps

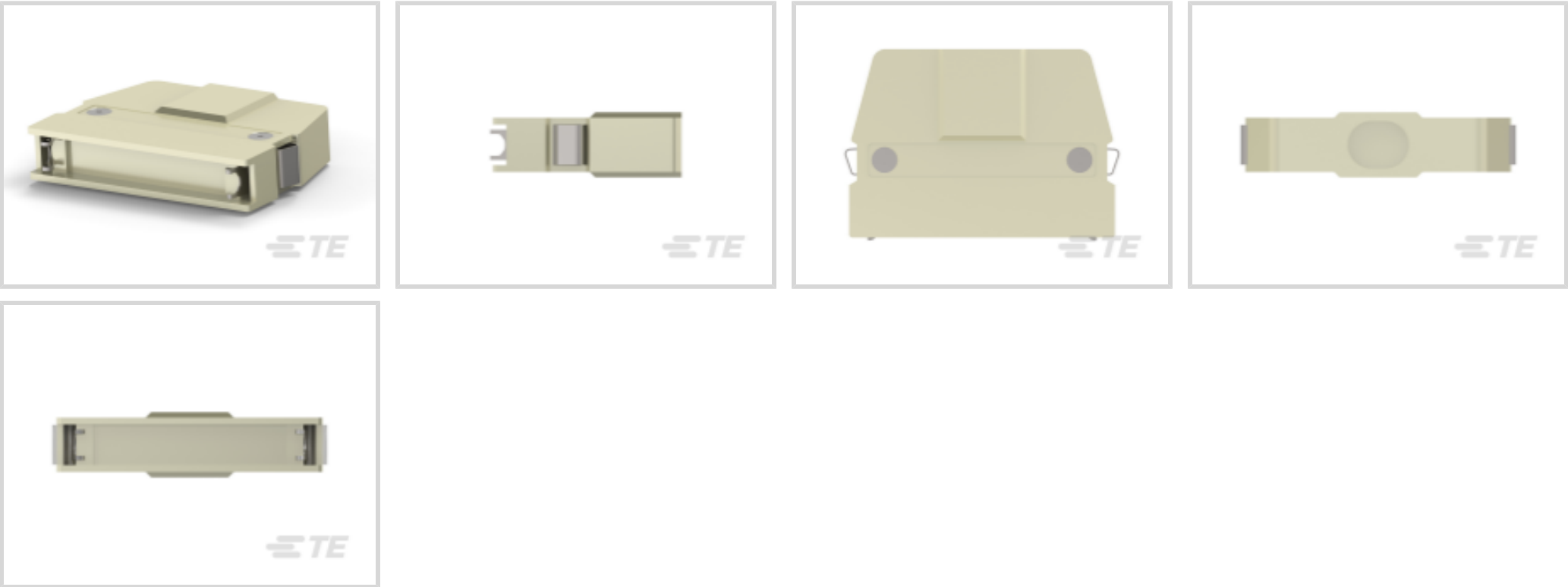

D-Shaped Connector Accessories: **Backshell Kit**

Number of Positions: **50**

Shielded: **Yes**

Cable Insulation Diameter Range: **10.16 mm [.4 in]**

Cable Exit Angle: **180° (In-Line)**

Features

Product Type Features

Latching Spring Material	Stainless Steel
Product Type	Hardware
D-Shaped Connector Accessories	Backshell Kit
Connector & Contact Terminates To	Wire & Cable

Configuration Features

Number of Positions	50
---------------------	----

Body Features

Strain Relief Clip Material	Steel
Backshell Plating Material	Nickel over Copper
Backshell Material	Zinc
Cable Exit Angle	180° (In-Line)

Dimensions

Cable Insulation Diameter Range	10.16 mm[.4 in]
---------------------------------	-----------------



Operation/Application

Shielded	Yes
----------	-----

Packaging Features

Packaging Quantity	1
Packaging Method	Bag

Other

Comment	Each backshell kit includes upper and lower backshells, two spring latches, one strain relief staple and two 2-56 screws. All are packaged unassembled, Meets SCSI-2 standards
---------	--

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JUN 2020 (209) SVHC > Threshold: Not Yet Reviewed
Halogen Content	Not Yet Reviewed for halogen content
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # CAT-AM7-2250
IDC D-Sub: Plug Assembly, Signal, 1.27 mm

TE Part # CAT-AM7-225072
IDC D-Sub: Receptacle Kit, Cable to Cable, Signal, 1.27 mm

TE Part # CAT-AM7-22507
IDC D-Sub: Connector Kit, Plug, Signal, 1.27 mm

TE Part # CAT-AM7-436507
IDC D-Sub: Receptacle Assembly, Panel Mount, Signal, 1.27 mm

TE Part # 5749210-5
50 50SR CABLE RCPT ASSY

TE Part # 749193-2
50 50SR KIT,ST,UK

TE Part # CAT-AM7-4365072
IDC D-Sub: Receptacle Kit, Panel Mount, Signal, 1.27 mm

TE Part # 749124-3
50-68 50SR STAPLE LP TIN

Also in the Series | **AMPLIMITE 0.50 Series**

D-Sub Backshells & Clamps(31)

D-Sub Covers(20)

D-Sub Locking & Mounting(8)

IDC D-Sub Connectors(77)

Insertion & Extraction Tools(1)

PCB D-Sub Connectors(196)

Customers Also Bought

TE Part #1658647-1
D-Sub Crimp: Plug, Signal, 15 Posn, Pin Size 20, Shell Size 2

TE Part #1658649-1
D-Sub Crimp Rcpt Signal 25 Posn, Socket Size 20, Shell Size 3

TE Part #1658686-3
D-Sub Conn Contacts: Socket, Phosphor Bronze, Signal, Size 22

TE Part #1-5750913-5
IDC D-Sub: Connector Kit, Plug, Signal, 1.27 mm





TE Part #1761028-5

D-Sub Receptacle Assembly: Right Angle, 1.27mm



TE Part #1-1879073-7

Power Resistor: Aluminum Housed, 75 Watt




TE Part #1676151-2

RN 0805 10K5 0.1% 10PPM 1KRL



TE Part #1-2176349-2

CRGCQ 2512 82R 1%

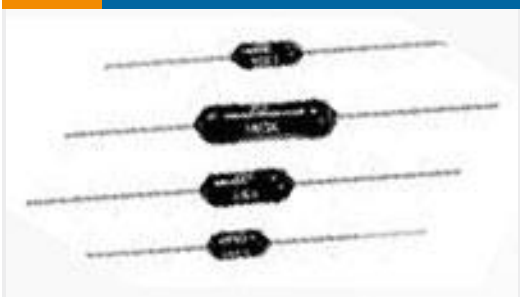

TE Part #9-1879663-1

H8 931R 0.1% 15PPM



TE Part #1658641-2

D-Sub Crimp: Plug, Signal, 50 Posn, Pin Size 20, Shell Size 5

Documents

Product Drawings

50 50SR KIT,ST,UK

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_5749193-2_O.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_5749193-2_O.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_5749193-2_O.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

AMPLIMITE Subminiature D Connectors - .050 Series Connector

English

AMPLIMITE .050 Series D-sub Connectors QRG

English

Product Environmental Compliance

TE Material Declaration

English

