


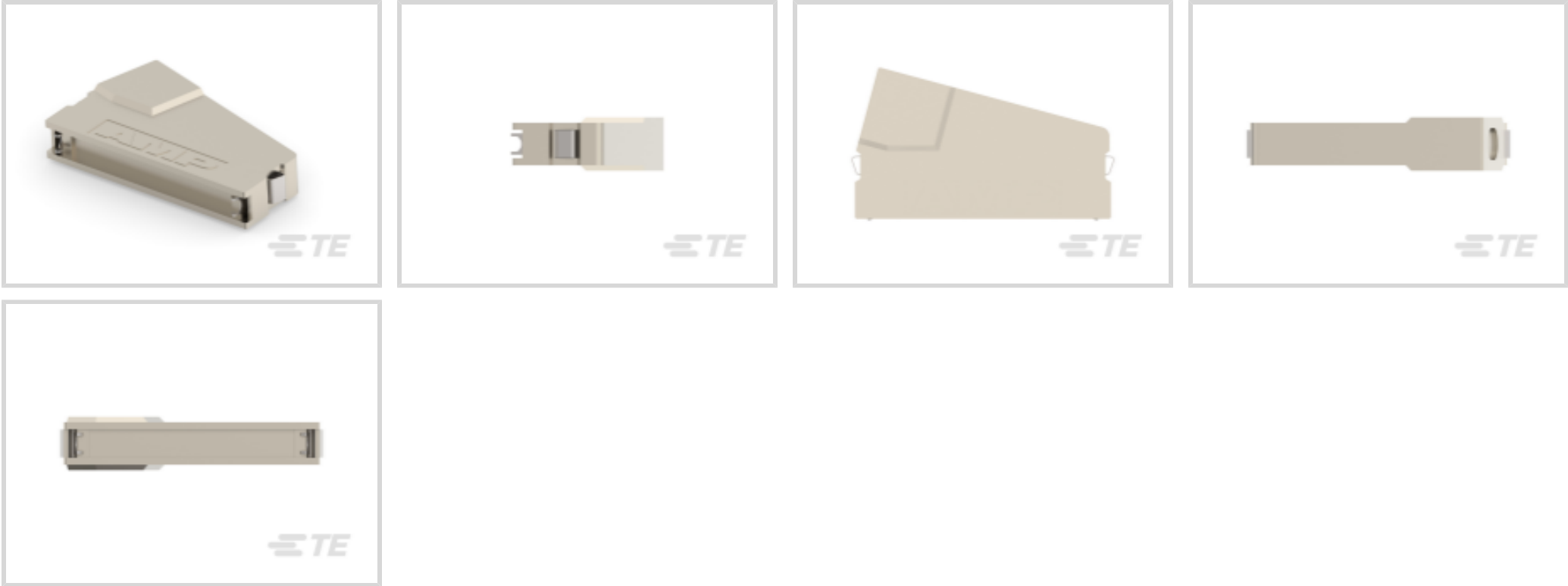

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # CAT-AM7-22507
IDC D-Sub: Connector Kit, Plug,
Signal, 1.27 mm

Customers Also Bought

TE Part #1658608-3
IDC D-Sub: Plug Assembly, Low
Profile, Signal, 2.77 mm

TE Part #1658621-3
16 NOVO MIL/CTR 15DP,LEAD FREE

TE Part #102387-9
40 MODIV HSG COMP DR .100 POL

TE Part #1-640518-0
03P MR II PLUG HSG V0 RED

TE Part #1-480426-0
04P CMNL CAP HSG F/H NATL

TE Part #2-87195-6
MOD IV RECP LP, 30 Au, TIN, RoHS

TE Part #1-640509-0
04P MR II CAP HSG V0 RED

TE Part #2-520103-2
ULTRA-FAST 250 ASSEMBLY TAB 22-
18 AWG BR

TE Part #3-520107-2
ULTRA-FAST 250 ASY TAB 16-14 AWG
TPBR

TE Part #9-2119784-5
CRIMPER INSULATION O PREMIUM
TPBR

Documents

Product Drawings
80 50SR KIT,75D,UK

English

CAD Files

3D PDF

English

Customer View Model

ENG_CVM_5749205-1_O.2d_dxf.zip



English

Customer View Model

[ENG_CVM_5749205-1_O.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_5749205-1_O.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[AMPLIMITE Subminiature D Connectors - .050 Series Connector](#)

English

[AMPLIMITE .050 Series D-sub Connectors QRG](#)

English

Product Specifications

[Application Specification](#)

English