

5749914-1 ✓ ACTIVE

AMPLIMITE | AMPLIMITE Kit


TE Internal #: 5749914-1

AMPLIMITE Kit, D-Sub Backshells & Clamps, Cable Clamp Kit, One-Piece Quick Snap, Compatible With Connector Shell Size 1

[View on TE.com >](#)



Connectors > D-Shaped Connectors > D-Sub Accessories > D-Sub Backshells & Clamps

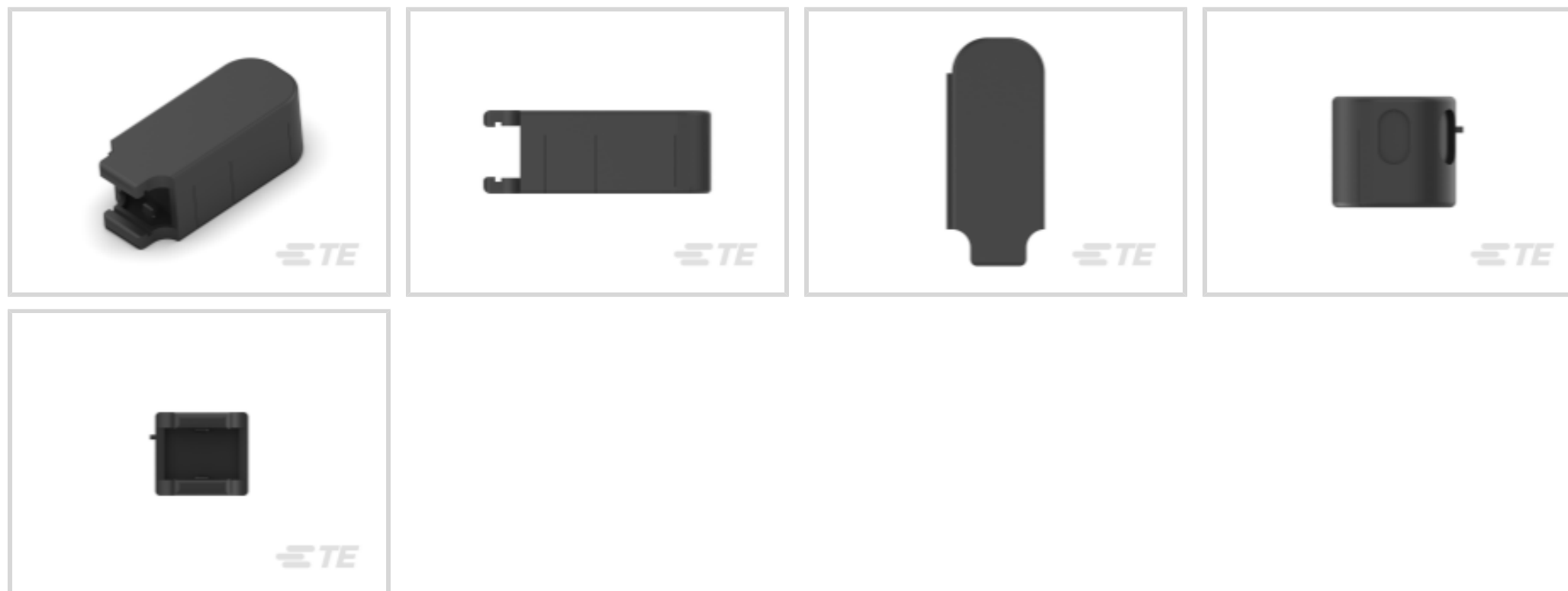

D-Shaped Connector Accessories: **Cable Clamp Kit**

Cable Clamp Type: **One-Piece Quick Snap**

Compatible With Connector Shell Size: **1**

Shielded: **No**

Cable Insulation Diameter Range: **1.91 – 6.35 mm [ .075 – .25 in ]**

## Features

### Product Type Features

Grommets	Without
Product Type	Accessory
D-Shaped Connector Accessories	Cable Clamp Kit

### Body Features

Shield Plating Material	None
Cable Clamp Material	Polypropylene
Retainer Clip Material	Stainless Steel
Color	Black
Cable Clamp Type	One-Piece Quick Snap
Cable Exit Angle	120°, 180° (In-Line)

### Mechanical Attachment

Screw & Hole Thread Size	4-40
--------------------------	------

### Dimensions

Cable Insulation Diameter Range	1.91 – 6.35 mm [.075 – .25 in]
---------------------------------	--------------------------------



### Operation/Application

Compatible With Connector Shell Size	1
Shielded	No

### Packaging Features

Packaging Quantity	1
Packaging Method	Bulk

### Other

Comment	For metal-shell connectors only., Kit Contains: 1 Hinged Cable Clamp, 2 Self-tapping Screws, 1 Strain Relief Clip, 1 Cable Exit Gate Plug (Used to close unused exit), 2 Retainer Clips and 2 Retainer Screws.
---------	----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------

### Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JUN 2018 (191) SVHC > Threshold: Not Yet Reviewed
Halogen Content	Not Yet Reviewed for halogen content
Solder Process Capability	Not applicable for solder process capability

#### Product Compliance Disclaimer


This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

## Compatible Parts



TE Part # 5-747905-5  
9 Rcpt Solder Cup, 30 gold, Ro

## Also in the Series | AMPLIMITE Kit

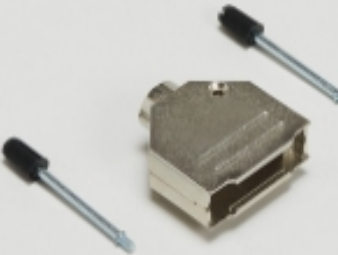


D-Sub Backshells & Clamps(136)



D-Sub Contact Accessories(1)



D-Sub Covers(3)



D-Sub Locking & Mounting(122)

## Customers Also Bought



TE Part #1658661-1  
D-Sub Crimp: Plug, Signal, 50 Posn, Pin Size 20, Shell Size 5



TE Part #1-66361-4  
TYPE III CONTACTS LP HIGH CURRENT



TE Part #1658537-3  
D-Sub Conn Contacts: Socket, Phosphor Bronze, Signal, Size 20




TE Part #746603-4  
64 EUROLATCH LEAD FREE



TE Part #170359-3  
MINI UNIVERSAL M-N-L PIN



TE Part #170361-3  
MINI UNIVERSAL M-N-L SOCKET

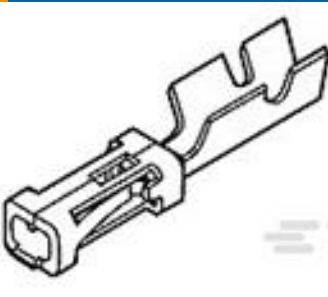

TE Part #1-87523-9  
MOD IV RECP LP



TE Part #1-1904045-2  
V23333Z1001A008-EV-100



## Documents

### Product Drawings

[CABLE CLAMP KIT,SZ 1,BULK PKG](#)

English

### CAD Files

[3D PDF](#)

3D

[Customer View Model](#)

[ENG\\_CVM\\_CVM\\_5749914-1\\_O.2d\\_dxf.zip](#)

English

[Customer View Model](#)

[ENG\\_CVM\\_CVM\\_5749914-1\\_O.3d\\_igs.zip](#)

English

[Customer View Model](#)

[ENG\\_CVM\\_CVM\\_5749914-1\\_O.3d\\_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

### Datasheets & Catalog Pages

[AMPLIMITE Subminiature D Connectors - Cable Connectors](#)

English

[AMPLIMITE Cable Connectors and Shielding Hardware Kits QRG](#)

English

### Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English

[AMPLIMITE Quik-Snap Backshell Kit](#)

English