



Connectors > D-Shaped Connectors > D-Sub Connectors > Crimp D-Sub Connectors >

D-Sub Crimp Recpt Signal 26 Posn, Socket Size 22, Shell Size 2



Connector & Housing Type: **Receptacle**

Connector System: **Cable-to-Cable**

Number of Positions: **26**

D-Sub Contact Size: **22**

D-Sub Shell Size: **2**

[All D-Sub Crimp Recpt Signal 26 Posn, Socket Size 22, Shell Size 2 \(5\)](#)

Features

Product Type Features

Grade	Standard
Grounding Indents	Without
Product Type	Connector
Shell Type	Front Metal Shell
Connector & Housing Type	Receptacle
Connector System	Cable-to-Cable
D-Sub Shell Size	2
Sealable	No
Connector & Contact Terminates To	Wire & Cable

Configuration Features

Number of Positions	26
---------------------	----

Body Features

Shell Material	Steel
Shell Plating Material	Tin
Insert Material	Thermoplastic

Contact Features



D-Sub Contact Size	22
--------------------	----

Mechanical Attachment

Mating Retention	With
Mating Retention Type	Clinch Nut, 4-40 UNC

Housing Features

Centerline (Pitch)	2.28 mm[.09 in]
--------------------	-----------------

Usage Conditions

Operating Temperature Range	-55 – 105 °C[-67 – 221 °F]
-----------------------------	----------------------------

Operation/Application

Shielded	Yes
Circuit Application	Signal

Industry Standards

Insert Flammability Rating	UL 94V-0
UL Flammability Rating	UL 94V-0

Packaging Features

Packaging Method	Carton
Packaging Quantity	100

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer



This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # CAT-038-DCPPS222
D-Sub Crimp: Plug, Signal, 26 Posn, Pin Size 22, Shell Size 2



TE Part # 5206471-1
CABLE CLAMP KIT,SZ 2

Customers Also Bought



TE Part #1658608-1
IDC D-Sub: Plug Assembly, Low Profile, Signal, 2.77 mm



TE Part #1658640-2
D-Sub Crimp Recpt Signal 50 Posn, Socket Size 20, Shell Size 5



TE Part #1658642-1
D-Sub Crimp: Plug, Signal, 9 Posn, Pin Size 20, Shell Size 1




TE Part #1658671-1
D-Sub Crimp: Plug, Signal, 26 Posn, Pin Size 22, Shell Size 2




TE Part #1658538-1
D-Sub Conn Contacts: Socket, Phosphor Bronze, Signal, Size 20



TE Part #1658623-9
40 NOVO MIL 30DP, LEAD FREE

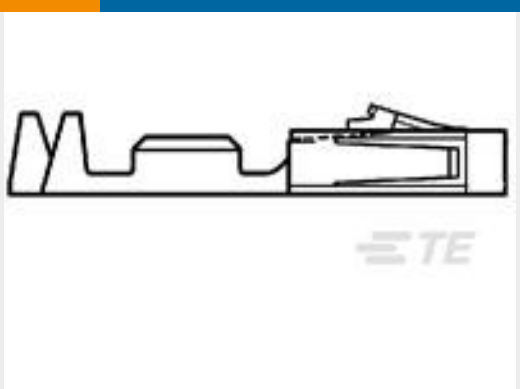

TE Part #104480-9
SHORT POINT RECP CONT LP

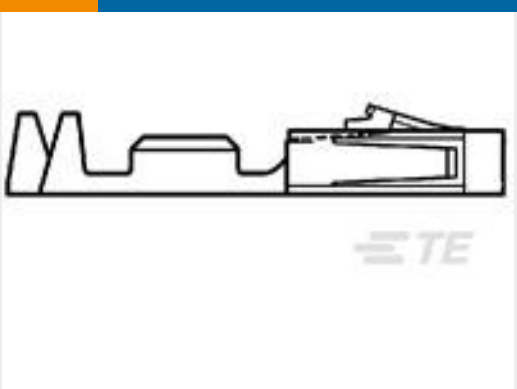

TE Part #104480-3
SHORT POINT CONT 15 DPLX STMPD



TE Part #1658662-1
D-Sub Crimp Recpt Signal 25 Posn,
Socket Size 20, Shell Size 3



TE Part #ZPF000000000008074
983-6K 10-05 S8

Documents

Product Drawings

RCPT ASSY,26P,HDP-22,CN

English

CAD Files

3D PDF

English

Customer View Model

ENG_CVM_5788816-1_O.2d_dxf.zip

English

Customer View Model

ENG_CVM_5788816-1_O.3d_igs.zip

English

Customer View Model

ENG_CVM_5788816-1_O.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

AMPLIMITE Subminiature D Connectors - Cable Connectors

English

AMPLIMITE Cable Connectors and Shielding Hardware Kits QRG

English

Product Specifications

Application Specification

English

Product Environmental Compliance

Product Compliance

English

Product Compliance

English

Instruction Sheets

Instruction Sheet (U.S.)



English

[Agency Approvals](#)

[UL Report](#)

English