



Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Wave solder capable to 265°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 5917629-2
AMP FH REC V 60P H-9 SIF




TE Part # 5917631-2
PLUG ASS'Y(V) 60P 1.27FHBB



TE Part # 5917628-2
REC ASS'Y(V) 60P 1.27FHBB

Also in the Series | **CHAMP .050 Series I**

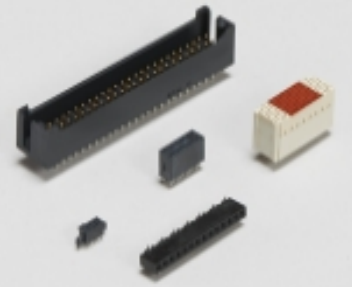

Board-to-Board Headers & Receptacles(120)




IDC D-Sub Connectors(6)



Standard Rectangular Connectors(1)


Customers Also Bought

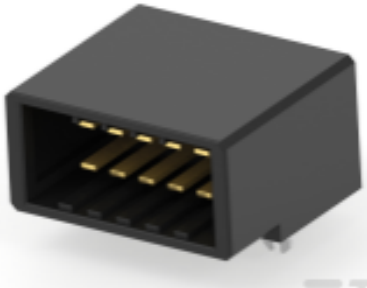


TE Part #1-178293-5
DYNAMIC 3100 HDR ASSY



TE Part #1123677-1
Z-STACK TYPE F16 ASSY 130P

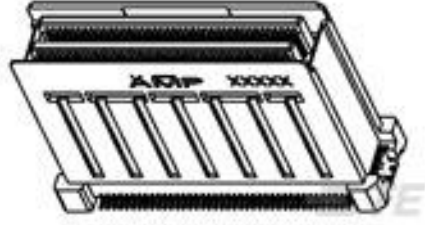


TE Part #6376609-1
MICRO STACK HDR ASSY 80P H=20

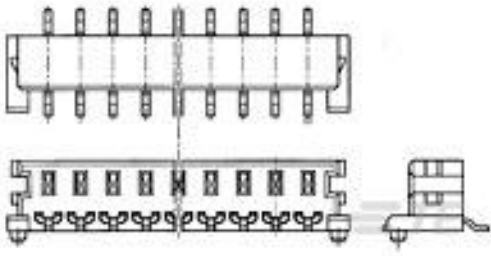


TE Part #1674000-2
HDR ASSY MINI VP 1.0MM W TO B



TE Part #1-2040516-5
DYNAMIC 1100 HDR ASSY

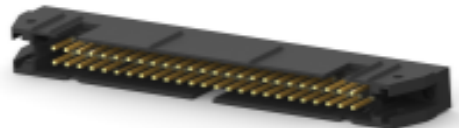

TE Part #1-5102160-1
AMP-LATCH UNIVERSAL HEADERS

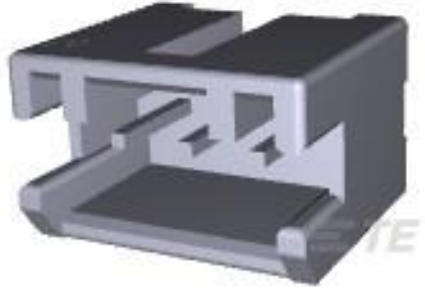

TE Part #1376478-3
2.5MM SIGNAL MATE CONN HEADER

TE Part #1554260-1
DUST CAP



TE Part #171883-1
13P MIC HSG 171358-1 MARKED



Documents

Product Drawings

REC ASS'Y 60P 1.27FHBB

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_5917630-2_B.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_5917630-2_B.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_5917630-2_B.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Environmental Compliance

TE Material Declaration

English