


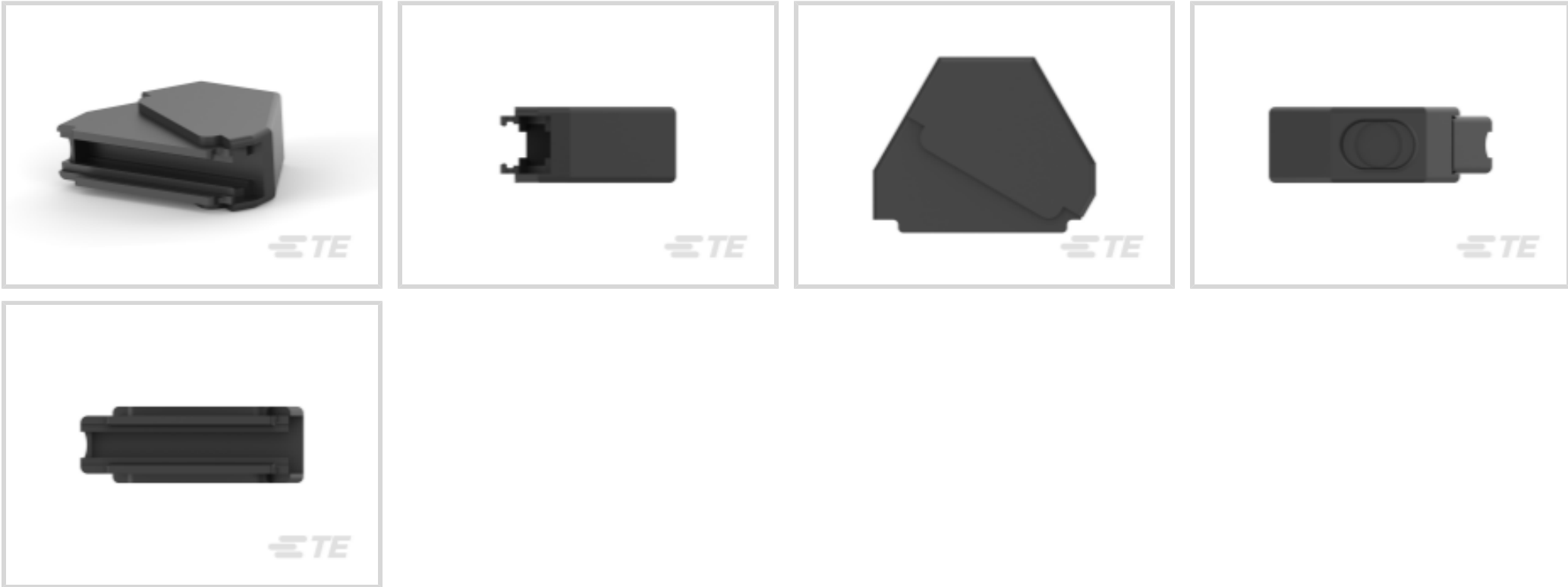

Connectors > D-Shaped Connectors > D-Sub Accessories > D-Sub Backshells & Clamps



D-Shaped Connector Accessories: **Cable Clamp Kit**

Compatible With Connector Shell Size: **4**

Shielded: **No**

Cable Insulation Diameter Range: **19.05 mm [.75 in]**

Cable Exit Angle: **180° (In-Line), 90° (Right Angle)**

Features

Product Type Features

Grommets	Without
Product Type	Accessory
D-Shaped Connector Accessories	Cable Clamp Kit
Sealable	No

Body Features

Cable Exit Angle	180° (In-Line), 90° (Right Angle)
------------------	-----------------------------------

Mechanical Attachment

Screw & Hole Thread Size	None
--------------------------	------

Dimensions

Cable Insulation Diameter Range	19.05 mm[.75 in]
---------------------------------	------------------

Operation/Application

Compatible With Connector Shell Size	4
Shielded	No



Packaging Features

Packaging Quantity	4
Packaging Method	Kit

Other

Comment	All parts are packaged unassembled., Each cable clamp assembly includes a yoke, male panel, female panel and four cable support gates. The cable diameter is adjustable by changing the cable support gates.
---------	--

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2020 (205) SVHC > Threshold: Not Yet Reviewed
Halogen Content	Low Bromine/Chlorine - Br and Cl < 900 ppm per homogenous material. Also BFR /CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # CAT-035-DCRSS204
D-Sub Crimp Recpt Signal 37 Posn,
Socket Size 20, Shell Size 4

Also in the Series | **AMPLIMITE Kit**

D-Sub Backshells & Clamps(136)

D-Sub Contact Accessories(1)

D-Sub Covers(3)

D-Sub Locking & Mounting(122)

Customers Also Bought

TE Part #1658653-1
D-Sub Crimp Recpt Signal 50 Posn,
Socket Size 20, Shell Size 5

TE Part #123339-000
B-106-1402

TE Part #1-640521-0
09P MR II PLUG HSG V0 RED

TE Part #104505-7
MTE PIN LP

TE Part #1-794772-0
10P MINI UMNL SEAL,DIE CUT

TE Part #1-2106123-2
CONTACT,Recept, SLC, Tin Plated,
Loose P

TE Part #1803019-5
CRIMPER, INSULATION O

TE Part #1-2134249-0
D3900 SPRING CLAMP REC 10P w
/oSEAL-typeA

TE Part #1-51692-6
N SERIES PLUG RG 217

TE Part #NB14254001
VERSAFIT-1-0-FSP



Documents

Product Drawings

HDE CBL CLMP KIT,SZ 4

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_745311-1_C.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_745311-1_C.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_745311-1_C.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

AMPLIMITE Subminiature D Connectors - Cable Connectors

English

AMPLIMITE Cable Connectors and Shielding Hardware Kits QRG

English

Product Environmental Compliance

TE Material Declaration

English

Instruction Sheets

Instruction Sheet (U.S.)

English

AMPLIMITE HDP-20 AND HDE-20 CONNECTORS THREE-PIECE AND TWO-PIECE

English