




Connectors > D-Shaped Connectors > D-Sub Accessories > D-Sub Backshells & Clamps

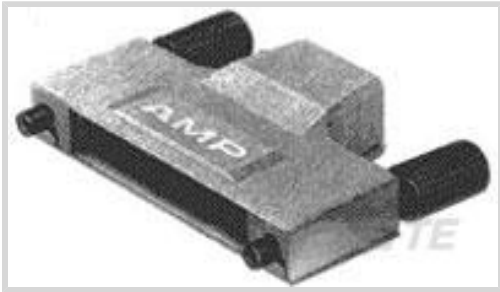

D-Shaped Connector Accessories: **Backshell Kit**

Number of Positions: **50**

Shielded: **Yes**

Cable Insulation Diameter Range: **10.16 mm [.4 in]**

Cable Exit Angle: **180° (In-Line)**

Features

Product Type Features

Grommets	With
Product Type	Hardware
D-Shaped Connector Accessories	Backshell Kit
Connector & Contact Terminates To	Wire & Cable

Configuration Features

Number of Positions	50
---------------------	----

Body Features

Strain Relief Clip Material	Carbon Steel
Color	Black
Backshell Plating Material	Nickel
Backshell Material	Zinc
Cable Exit Angle	180° (In-Line)

Mechanical Attachment

Jackscrew Material	Steel
Mating Connector Lock	With
Screw Material	Stainless Steel
Mating Connector Lock Type	Male Jackscrew
Jackscrew Plating Material	Zinc



Jackscrew Head Material	PVC
Screw & Hole Thread Size	2-56

Dimensions

Cable Insulation Diameter Range	10.16 mm[.4 in]
---------------------------------	-----------------

Operation/Application

Shielded	Yes
----------	-----

Packaging Features

Packaging Method	Individual, Kit
------------------	-----------------

Other

Comment	Each backshell kit includes upper and lower backshells, two jackscrews, one strain relief staple and two 2-56 screws. All are packaged unassembled
---------	--

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Not Compliant
EU ELV Directive 2000/53/EC	Not Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2018 (181) SVHC > Threshold: Not Yet Reviewed
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



Compatible Parts

TE Part # 5749080-1
50 50SR BSHLL KIT, M/J-SCR

TE Part # 749067-4
50SR JACKSCREW ASSY, MALE

Also in the Series | **AMPLIMITE 0.50 Series**

D-Sub Backshells & Clamps(31)

D-Sub Covers(20)

D-Sub Locking & Mounting(8)

IDC D-Sub Connectors(77)

Insertion & Extraction Tools(1)

PCB D-Sub Connectors(196)

Customers Also Bought

TE Part #1-6609000-3
CORCOM EEA SERIES IEC FILTERED INLETS

TE Part #2322337-1
NanoRF, BP, 18 POS, SS

TE Part #1-6609103-7
CORCOM P SERIES MULTI-FUNCTION INLET FIL

TE Part #212522-1
PLUG ASSY, 21C1, AMPLIMITE







TE Part #1-51692-6
N SERIES PLUG RG 217



TE Part #YDIV46E19-11PNC009
PLUG ASSY

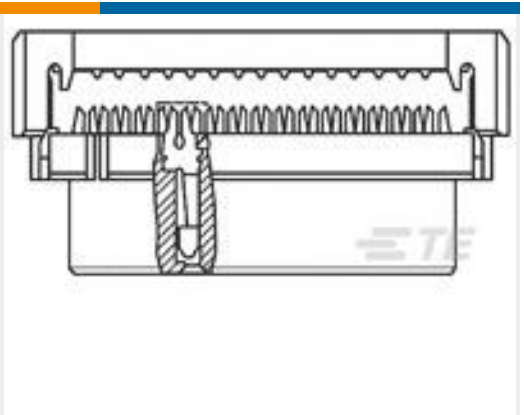

TE Part #1-111626-0
044 2MM 30DP FT

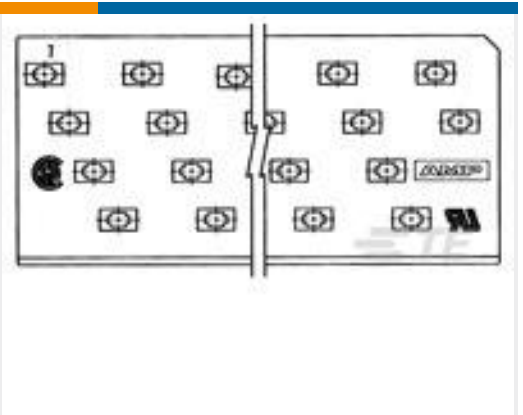

TE Part #111359-5
26 PDL BRD COVER



TE Part #1-1437598-1
SKT332AEL01=#101 SKT-33-2 AEL



TE Part #208498-1
RECEPT MODULE ASSY FOR RIBBON

Documents

Product Drawings

50 50SR BSHELL KIT,MALE JSCREW

English

CAD Files

3D PDF

English

Customer View Model

ENG_CVM_749080-1_E.2d_dxf.zip

English

Customer View Model

ENG_CVM_749080-1_E.3d_igs.zip

English

Customer View Model

ENG_CVM_749080-1_E.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Application Specification

English

Product Environmental Compliance

TE Material Declaration

English

Instruction Sheets

Instruction Sheet (U.S.)



English

[Instruction Sheet \(U.S.\)](#)

English

[Instruction Sheet \(U.S.\)](#)

English

[Instruction Sheet \(U.S.\)](#)

English

[Agency Approvals](#)

[UL Report](#)

English