



Connectors > D-Shaped Connectors > D-Sub Accessories > D-Sub Backshells & Clamps



D-Shaped Connector Accessories: **Backshell Kit**

Number of Positions: **50**

Shielded: **Yes**

Cable Insulation Diameter Range: **10.16 mm [.4 in]**

Cable Exit Angle: **180° (In-Line)**

Features

Product Type Features

Latching Spring Material	Stainless Steel
Product Type	Connector
D-Shaped Connector Accessories	Backshell Kit
Connector & Contact Terminates To	Wire & Cable

Configuration Features

Number of Positions	50
---------------------	----

Body Features

Boot Material	PVC
Strain Relief Clip Material	Steel
Backshell Plating Material	Nickel over Copper
Backshell Material	Zinc
Cable Exit Angle	180° (In-Line)

Mechanical Attachment

Mating Connector Lock	With
Mating Connector Lock Type	Spring Latch
Screws and Retainer Clips	With
Screw Material	Stainless Steel

Dimensions



Cable Insulation Diameter Range	10.16 mm[.4 in]
---------------------------------	-----------------

Operation/Application

For Use With	Cable
Shielded	Yes

Industry Standards

Cover Flammability Rating	UL 94V-0
---------------------------	----------

Packaging Features

Packaging Quantity	1
Packaging Method	Bag

Other

Comment	Each backshell kit includes upper and lower backshells, two spring latches, one strain relief staple and two 2-56 screws. All are packaged unassembled, Meets SCSI-2 standards
---------	--

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Not Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JUN 2018 (191) SVHC > Threshold: Not Yet Reviewed
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous



materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

TE Part # 5749193-2
50 50SR KIT,ST,UK

Also in the Series | AMPLIMITE 0.50 Series

D-Sub Backshells & Clamps(31)

D-Sub Covers(20)

D-Sub Locking & Mounting(8)

IDC D-Sub Connectors(77)

Insertion & Extraction Tools(1)

PCB D-Sub Connectors(196)

Customers Also Bought

TE Part #1658526-2
609-0641LF FEM SOCKET,LEAD FREE

TE Part #2102352-6
CeeLok FAS-T, Receptacle Kit, ZnNi, B

TE Part #2-32589-1
PIDG SPADE TONGUE TERMINALS

TE Part #1-2308265-5
QLPIN FOR D-SUB W/ THREADED INSERTS






TE Part #YDTS26W23-21SNV001
D38999: Straight Plug, 23-21 Insert



TE Part #2-1633730-4
CRIMPER, WIRE F .062 F



TE Part #2-456134-2
CRIMPER, INSULATION "F"(.110")

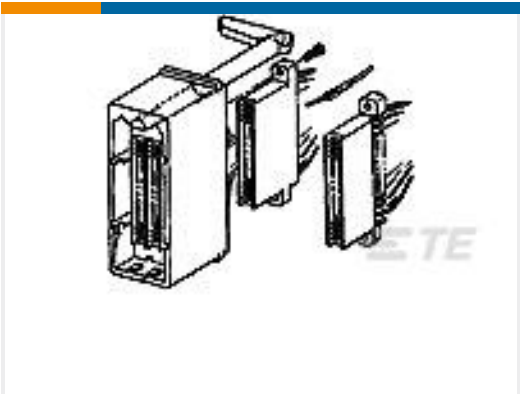

TE Part #207226-1
120 POS ZERO ENTRY CONN

TE Part #2102349-3
CONTACT PIN SIZE 24-26 PLAT

TE Part #2102350-5
CONTACT SOCKET SIZE 24-26 HOOD

Documents

Product Drawings

50 50SR KIT,ST,UK

English

CAD Files

3D PDF

English

Customer View Model

ENG_CVM_749193-2_H.2d_dxf.zip

English

Customer View Model

ENG_CVM_749193-2_H.3d_igs.zip

English

Customer View Model

ENG_CVM_749193-2_H.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Application Specification

English

Instruction Sheets

Instruction Sheet (U.S.)

English

Instruction Sheet (U.S.)

English



[Instruction Sheet \(U.S.\)](#)

English

[Instruction Sheet \(U.S.\)](#)

English