



Terminals & Splices > Terminal Housings, Insulation Sleeves & Blocks > Crimp Terminal Housings



Terminal & Splice Type: **Receptacle**
Housing Type: **Receptacle**
Number of Crimp Terminal Housing Positions: **1**
Crimp Terminal Housing Terminal Orientation: **Straight**
Crimp Terminal Housing Housing Color: **Black**

Features

Product Type Features

Product Type	Terminal Housing
Housing Type	Receptacle
Sealable	No
Insulated	No

Configuration Features

Number of Crimp Terminal Housing Positions	1
--	---

Body Features

Crimp Terminal Housing Housing Color	Black
Crimp Terminal Housing Mating Retention	Without
Crimp Terminal Housing Mating Alignment	Without

Contact Features

Terminal & Splice Type	Receptacle
Crimp Terminal Housing Terminal Orientation	Straight



Mechanical Attachment

Crimp Terminal Housing Mounting Style	Cable Mount (Free-Hanging)
---------------------------------------	----------------------------

Housing Features

Crimp Terminal Housing Housing Material	PBT
---	-----

Dimensions

Length	18 mm[.71 in]
--------	---------------

Packaging Features

Packaging Quantity	1000
--------------------	------

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 925015-1
FF 110 REC HSG 3P NYLON BLACK

TE Part # 626062
FASTIN-ON HOUSING REC PA66 NATURAL

TE Part # 173271-2
250 SERIES HORN CONNECTOR, PLUG HSG

TE Part # 926728-1
FF 110 REC HSG 4P NYLON BLACK

TE Part # 1-172131-1
FF 250 REC HSG 3P NYLON NAT

TE Part # 968864-1
FF 110 REC HSG 2P NYLON NAT

TE Part # 140885-5
FF 250 REC HSG 6P NYLON BLACK

TE Part # 176987-2
FF 250 PLUG HSG 1P NYLON BLACK

TE Part # 1982857-1
FASTON HOUSING

TE Part # 626064-5
ISOLADOR

Also in the Series | FASTON 187

Crimp Terminal Housings(40)

Insertion & Extraction Tools(1)

Joints & Splices(1)



PCB Terminals(48)

Quick Disconnects(222)

Splices(1)

Customers Also Bought

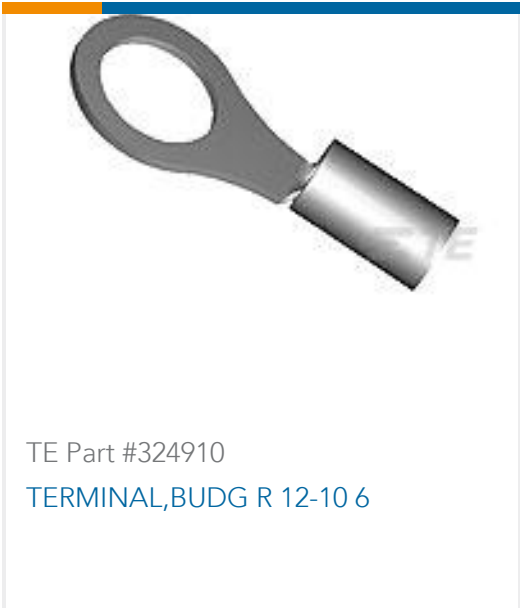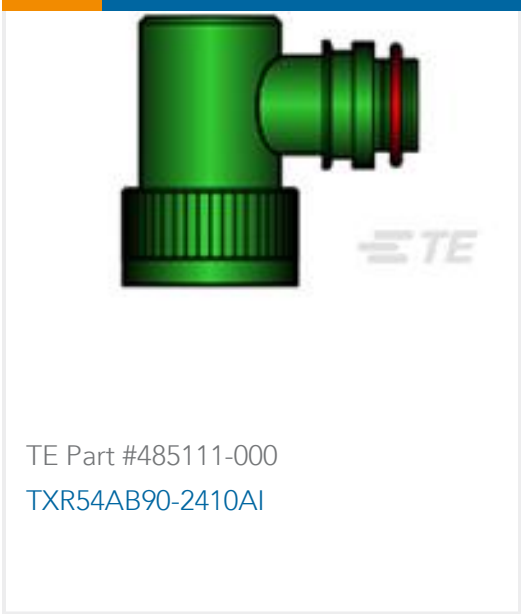

 TE Part #324910 TERMINAL,BUDG R 12-10 6	 TE Part #883745-000 TXR40AB00-1618AI	 TE Part #6-5173279-3 AMPLIMITE D-Sub Receptacle Assembly: Vertical, 1.27mm	 TE Part #YDTS26W17-08BNV001 D38999: Straight Plug, 17-08 Insert
 TE Part #D14846-000 82A0813-6-9	 TE Part #1982857-1 FASTON HOUSING	 TE Part #843781-000 82A0813-4-9	 TE Part #828923-000 82A0813-8-9
 TE Part #CA0866-000 TXR54AB00-2807AI	 TE Part #485111-000 TXR54AB90-2410AI		

Documents

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1982859-1_A.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1982859-1_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1982859-1_A.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

FASTIN-FASTON CONN. .110 INCH, .187 INCH, .250 INCH, .375 INCH SRS.

English

Product Specification

English

1982859-1

FASTON 187, Crimp Terminal Housings, Receptacle, Receptacle, 1 Position, Straight,
Black Crimp Terminal Housing Housing Color, PBT

