




Terminals & Splices > Splices

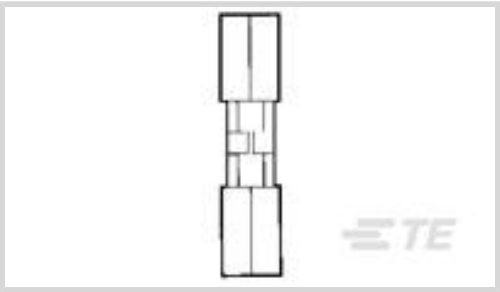

Splice Product Type: **Splice**
Terminal & Splice Type: **Splice**
Wire Size: **.2 – .6 mm²**
Sealable: **No**

Features

Product Type Features

Splice Product Type	Splice
Sealable	No
Splice Type	Butt Splice
Serrated	Yes
Splice Accessory Type	Splice
Splice Barrel Type	Closed Barrel
Splice Wire/Cable Type	Copper
Insulated	No
Support Style	Non - Insulation Support

Body Features

Weight per Piece	.332 g
Plating Material	Tin
Splice Features	Strap
Splice Material	Copper

Contact Features

Contact Plating Material	Tin
Terminal & Splice Type	Splice

Mechanical Attachment

Wire Insulation Support	Without
-------------------------	---------



Dimensions

Outside Diameter	2.67 mm[.105 in]
Wire Size	320 – 1290 CMA
Barrel Inside Diameter	1.09 mm[.043 in]
Splice Material Thickness	.6 mm[.024 in]
Splice Overall Length	12.45 mm[.49 in]

Usage Conditions

Insulation Requirement	Uninsulated
High Temperature Rating	170 °C[338 °F]
Operating Temperature Range	170 °C[338 °F]

Operation/Application

Heavy Duty	No
------------	----

Industry Standards

Government Qualified Splice	No
-----------------------------	----

Packaging Features

Packaging Quantity	1000
Splice Packaging Method	Loose Piece

Other

Military Category	No
-------------------	----

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability



Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



REPRESENTATION ONLY

TE Part # 69363
DAHT STRATO SOLIS 26-20 ASSY


Customers Also Bought



TE Part #1658646-1
D-Sub Crimp Recpt Signal 9 Posn,
Socket Size 20, Shell Size 1



TE Part #2-31890-1
PIDG RING TONGUE TERMINALS

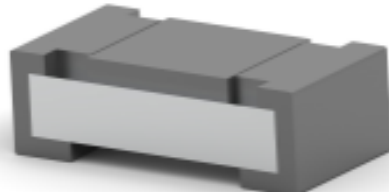

TE Part #2-2176051-8
Thick Film Resistor: Current Sense



TE Part #1-5745172-3
AMPLI CBL CLMP KIT



TE Part #2-321801-3
SOLIS BUTT 22-16 COMM 22-18MIL



TE Part #1-770904-1
MINI UMNL SOK 22-18AWG AU LF



TE Part #2029185-1
CMNL SKT W/INDENTED SIDES



TE Part #2-604772-9
CABLE TIE, NATURAL, 8" L, 1000/PK



Documents

Product Drawings

SPLICE,SOLIS BUTT STRAP 24-20

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_324001_G.2d_dxf.zip

English

Customer View Model

ENG_CVM_324001_G.3d_igs.zip

English

Customer View Model

ENG_CVM_324001_G.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Environmental Compliance

SPLICE,SOLIS BUTT STRAP 24-20

English

SPLICE,SOLIS BUTT STRAP 24-20

English

Agency Approvals

UL Report

English