

FASTON 187

TE Internal #: 42373-3

TE Internal Description: FASTON 187 16-20AWG NPST

[View on TE.com >](#)



Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2019 (197) SVHC > Threshold: Not Yet Reviewed
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Also in the Series | **FASTON 187**



Crimp Terminal Housings(40)



Insertion & Extraction Tools(1)



Joints & Splices(1)



PCB Terminals(48)




Quick Disconnects(222)



Splices(1)

Customers Also Bought

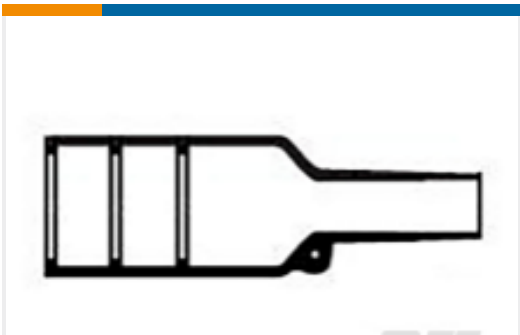

TE Part #438567-000
Bulbous Heat Shrink Boots: Lipped, Straight




TE Part #633417-000
TXR54AC00-1005AI




TE Part #610007-000
TXR54AC00-1004BI




TE Part #CC2649-000
B-106-1803CS50

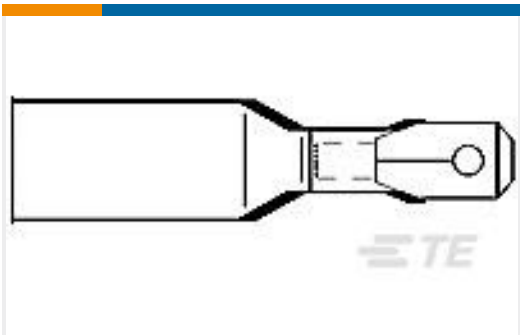


TE Part #CC2630-000
B-106-4631CS100

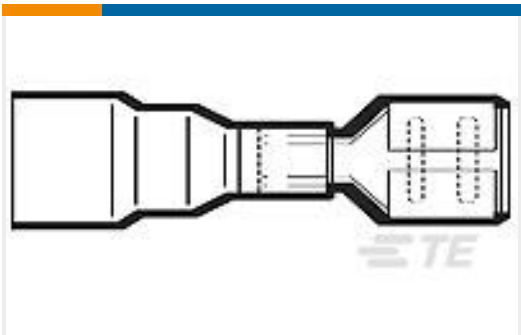


TE Part #CC2628-000
B-106-3631CS100

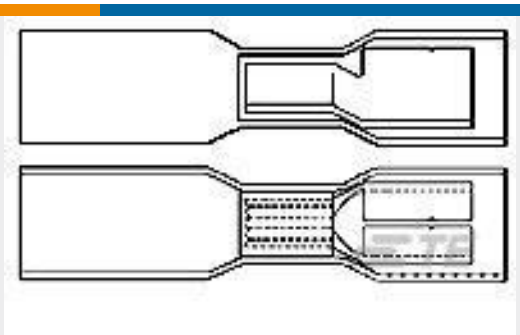

TE Part #CC2632-000
B-106-8401CS100

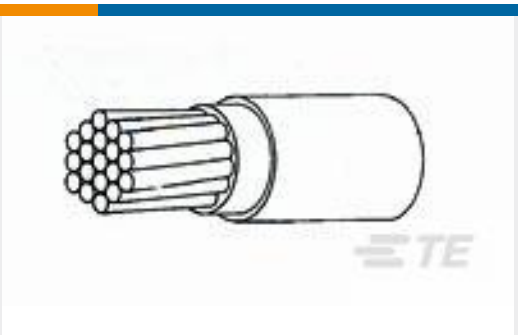

TE Part #2828393002
44A0111-24-95

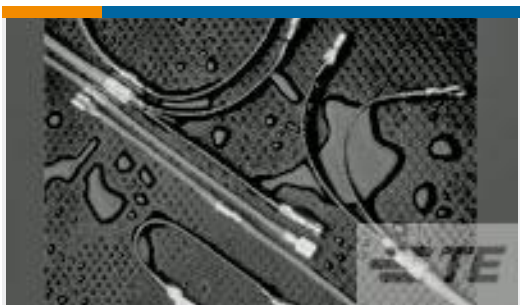

TE Part #CC2637-000
B-106-1802CS100



TE Part #4-1579007-1
EXTRACTION TOOL

Documents



Product Drawings
FASTON 187 16-20AWG NPST

English

CAD Files
3D PDF

3D

Customer View Model
ENG_CVM_CVM_42373-3_AY.2d_dxf.zip

English

Customer View Model
ENG_CVM_CVM_42373-3_AY.3d_igs.zip

English

Customer View Model
ENG_CVM_CVM_42373-3_AY.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages
82004 FASTON Terminals (Insulated and Uninsulated) Catalog - FASTON Receptacles Section

English

Product Specifications
Application Specification

English

Wire Preparation And Crimp Inspection Guide

English

Application Specification

English

Agency Approvals
UL

English