




Connectors > D-Shaped Connectors > D-Sub Accessories > Locking & Mounting

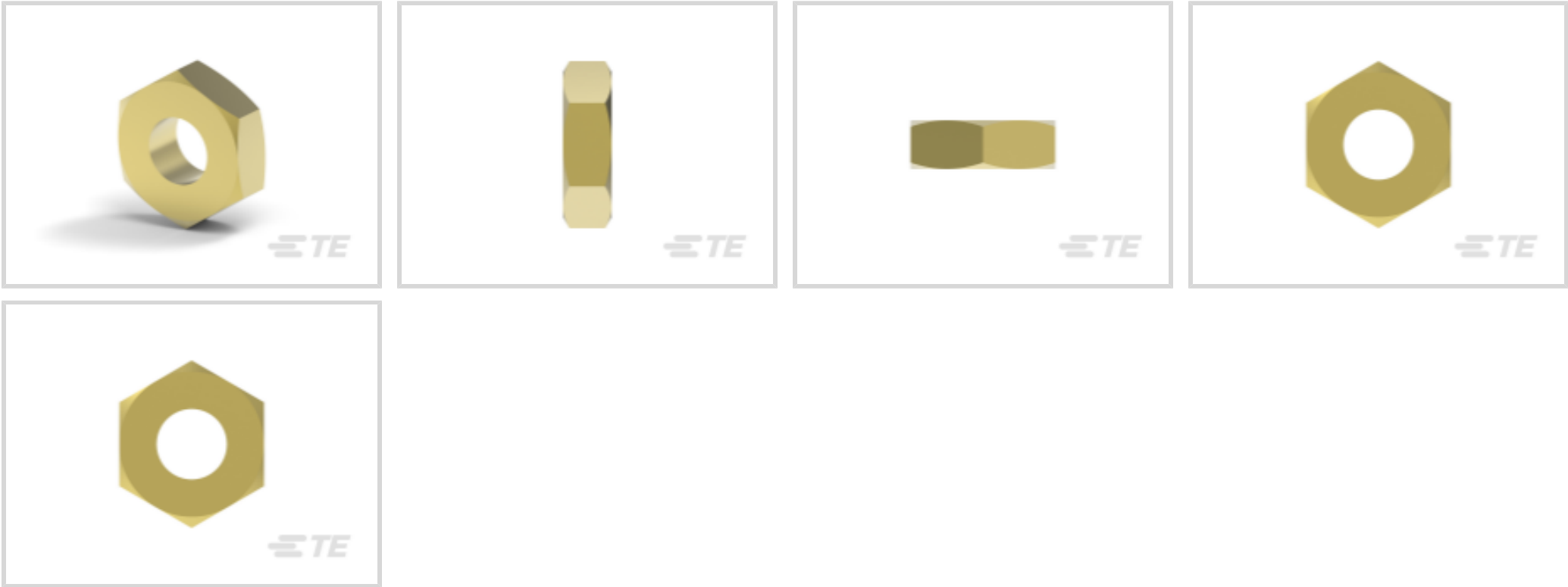

D-Shaped Connector Accessories: **Hex Nut**

Features

Product Type Features

Product Type	Accessory
D-Shaped Connector Accessories	Hex Nut

Mechanical Attachment

Screw & Hole Thread Size	4-40
--------------------------	------

Packaging Features

Packaging Quantity	10000
Packaging Method	Package

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC



Free

Solder Process Capability

Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 5205821-3
NUT,4-40,PLATED

Also in the Series | AMPLIMITE Kit



D-Sub Backshells & Clamps(136)



D-Sub Contact Accessories(1)



D-Sub Covers(3)




D-Sub Locking & Mounting(122)

Customers Also Bought




TE Part #1-5499923-0
AMP-LATCH UNIVERSAL HEADERS

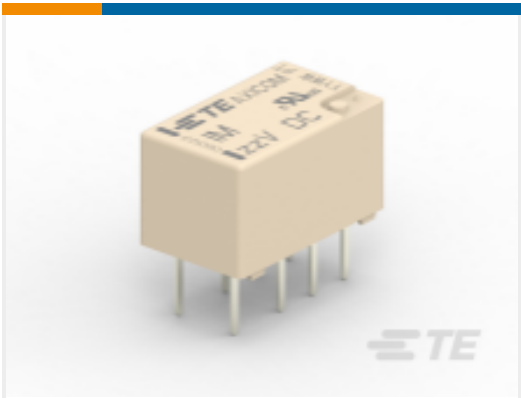

TE Part #1-1462038-2
Narrow Signal Relay 2 Form C, 2 CO Cont



TE Part #10207018-00
Compact Water Resistant Pressure Sensor

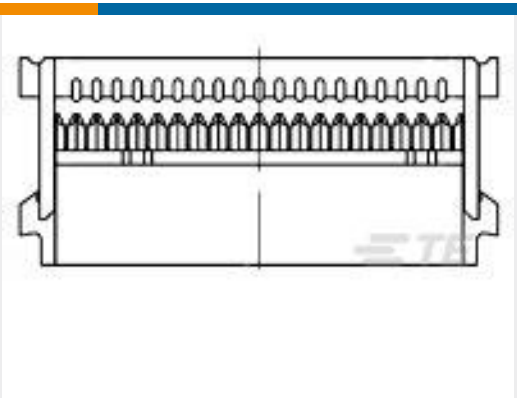

TE Part #1-1658526-2
609-2030LF FEM SOCKET,LEAD FREE



TE Part #1-87215-0
02 MODII HDR DRST UNSHRD .100

TE Part #1-282834-2
TERMI-BLOK PCB MOUNT, 90 12P.

TE Part #1-2176308-0
RP 1E 0.1W 165K 0.1% 25PPM 5K RL

TE Part #1624353-2
NTC0805 5% 22K

TE Part #1-208223-0
CPC SERIES 1 POSTED

TE Part #YDTS20W15-05PNV001
D38999: Square Flange, 15-05 insert

Documents

Product Drawings
HEX NUT,4-40,PLATED

English

CAD Files
3D PDF

3D

Customer View Model
ENG_CVM_CVM_5205821-2_O.2d_dxf.zip

English

Customer View Model
ENG_CVM_CVM_5205821-2_O.3d_igs.zip

English

Customer View Model
ENG_CVM_CVM_5205821-2_O.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications
Application Specification

English