



AMP

TE Internal #: 1901611-2

Portable Crimp Tools, Premium Crimp Tooling, Not Releasable, Not Adjustable, Fixed In Tool, TE Product Specification (114-) / MIL Spec

[View on TE.com >](#)

Application Tooling > Portable Crimp Tools



Tool Grade: **Premium Crimp Tooling**

Ratchet Configuration: **Not Releasable, Not Adjustable**

Die Sets Type: **Fixed In Tool**

Specification Type: **MIL Spec, TE Product Specification (114-)**

TE Certification: **Yes – Certificate Included**

Features

Other

Crimp Form-Wire Barrel Type	Closed Barrel - Confined Crescent
Tool Grade	Premium Crimp Tooling
Ratchet Configuration	Not Releasable, Not Adjustable
Die Sets Type	Fixed In Tool
Specification Type	MIL Spec, TE Product Specification (114-)
TE Certification	Yes – Certificate Included
Power Technology Type	Battery, Electric, Manual
Tooling Type	CERTI-CRIMP II, Straight Action Hand Tool

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)













EU RoHS Directive 2011/65/EU	Out of Scope
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JUN 2020 (209) SVHC > Threshold: Not Yet Reviewed


Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

 <p>TE Part # 152895 20 PIDG RT NO 6 STUD PURPL</p>	 <p>TE Part # 50832 TERMINAL,PIDG PTFE R 22-20 8</p>	 <p>TE Part # 1-332433-0 TERMINAL,PIDG PTFE R AU 22-20 6</p>	 <p>TE Part # 151439 PIDG 22 RING #6</p>
 <p>TE Part # 1577618-1 TERMINAL RT PIDG PEEK STRATO 24-22 AWG</p>	 <p>TE Part # 1577625-1 TERMINAL RT PIDG PEEK STRATO 20 AWG</p>	 <p>TE Part # 1577626-1 TERMINAL RT PIDG PEEK STRATO 20 AWG</p>	 <p>TE Part # 1577616-1 TERMINAL, PEEK PIDG STRATO, 24-22AWG</p>
 <p>TE Part # 1577619-1 TERMINAL RT PIDG PEEK STRATO 24-22 AWG</p>	 <p>TE Part # 50832-1 TERMINAL,PIDG PTFE R 22-20 10</p>	 <p>TE Part # 1577623-1 TERMINAL, PEEK PIDG STRATO, 20AWG</p>	 <p>TE Part # 1577620-1 TERMINAL RT PIDG PEEK STRATO 24-22 AWG</p>

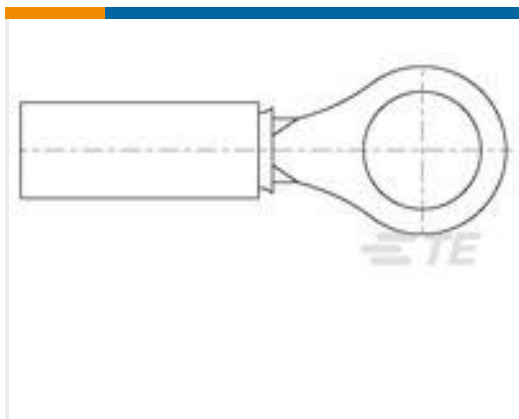TE Part # 1577624-1
TERMINAL RT PIDG PEEK STRATO 20 AWG



TE Part # 1577621-1
TERMINAL RT PIDG PEEK STRATO 24-22 AWG



TE Part # 50831
TERMINAL, PIDG PTFE R 22-20 4



TE Part # 1-332434-0
TERMINAL, PIDG PTFE R AU 22-20




TE Part # 151458
TERMINAL R T PIDG NYL AWG 22 #



TE Part # 1577622-1
TERMINAL, PEEK PIDG STRATO, 20AWG



TE Part # 50831-1
TERMINAL, PIDG PTFE R 22-20 6



TE Part # 151438
PIDG 22 RING #4


Customers Also Bought



TE Part #354940-1
PRO-CRIMPER III FRAME W/O DIES



TE Part #47387
DAHT PG PIDG 20-14 ASSY

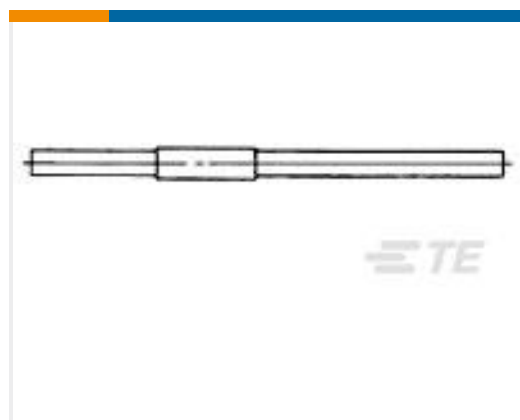

TE Part #204760-1
SEALING PLUG, SIZE 22



TE Part #45730
SADAHT STRATO 26-24 ASSY



TE Part #1901600-1
CCII PIDG STRATO 18-16 ASSY




TE Part #1901600-2
CCII PIDG STRATO 18-16 ASSY




TE Part #1901611-1
CCII PIDG STRATO 24-20 ASSY



TE Part #ZPF00000000017932
FDPA 50-10-6 SN-K-A246



TE Part #169404
CERTI-LOK DIE



TE Part #350877-000
55PC2136-24-2/4/6-9CS2502

Documents



Datasheets & Catalog Pages

[CERTI-CRIMP II-Premium-August-1-1773864-7](#)

English

[Crimp Term Whitepaper-Use the Right Tool 1-1773953-1](#)

English

[Bottoming Dies](#)

English

[CRIMPING WHERE FORM MEETS FUNCTION](#)

English

Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English