




Application Tooling > Spare & Wear Tooling

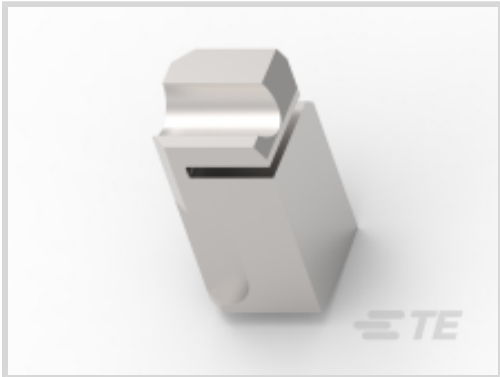

Applicator & Product Style: **Heavy Duty Mini (HDM)**

Features

Other

Applicator & Product Style	Heavy Duty Mini (HDM)
----------------------------	-----------------------

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>




Compatible Parts

 TE Part # 2-2151356-1 OCEAN_2.0_APPLICATOR-S-110F160F	 TE Part # 2-2151356-2 OCEAN_2.0_APPLICATOR-S-110F160F	 TE Part # 2151356-1 OCEAN_2.0_APPLICATOR-S-110F160F	 TE Part # 2151356-2 OCEAN_2.0_APPLICATOR-S-110F160F
 TE Part # 466634-4 HDM 5SMPR042F090F G	 TE Part # 7-2151356-2 OCEAN_2.0_APPLICATOR-S-110F160F	 TE Part # 1385039-3 HDM 8SMPR062F090F G	 TE Part # 1385056-1 HDM 8SMPO047F055F T
 TE Part # 1385056-3 HDM 8SMPR047F055F G	 TE Part # 1385172-1 HDM 5SMPO055F055F LM	 TE Part # 1385172-3 HDM 5SMPR055F055F G	 TE Part # 1385194-3 HDM 5SMPR055F070F G
 TE Part # 1385286-3 HDM 5SMPR070F102F G	 TE Part # 1385375-2 HDM 8SMPR062F100O K	 TE Part # 1385378-3 HDM 8SMPR042F070O G	 TE Part # 1385385-1 HDM 5SMPO073F090O LM
 TE Part # 1385385-2 HDM 5SMPR073F090O K	 TE Part # 1385385-3 HDM 5SMPR073F090O G	 TE Part # 1385401-3 HDM 8SMPR042F055F G	 TE Part # 1385534-2 HDM SMPR042F K

Customers Also Bought




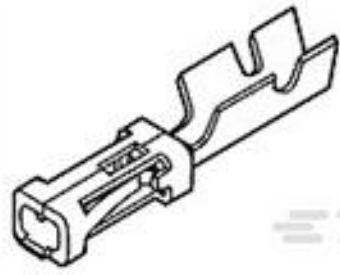

TE Part #87309-9
MOD V RECP PLTD 30 AU




TE Part #1-456405-3
CRIMPER WIRE .080 F

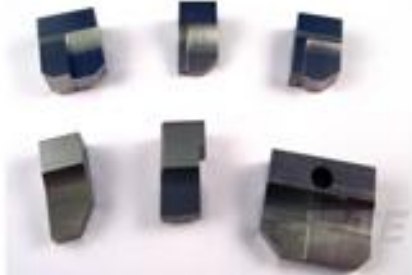

TE Part #2-690471-9
COMB ANVIL



TE Part #1-690474-9
SHEAR BLADE

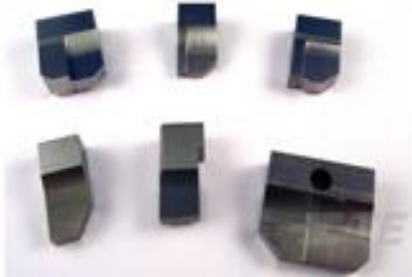

TE Part #1333204-1
ANVIL, COMBINATION .080



TE Part #1633966-2
CRIMPER, INSUL O



TE Part #1803095-5
FLOATING SHEAR, FRONT



ANVIL
REPRESENTATION ONLY

TE Part #1803293-7
ANVIL, COMBINATION DEUTCH
STYLE



TE Part #1-1490019-5
CRIMPER, WIRE (.090" 'F')



TE Part #1320920-1
SHEAR HOLDER, REAR

Documents

Datasheets & Catalog Pages
CRIMPING WHERE FORM MEETS FUNCTION

English

Instruction Sheets
Instruction Sheet (U.S.)

English