

525651 ✓ ACTIVE

AMP

TE Internal #: 525651

Portable Crimp Tools, Premium Crimp Tooling, Not Releasable, Not Adjustable, Fixed In Tool, TE Product Specification (114-), Battery / Manual

[View on TE.com >](#)



Application Tooling > Portable Crimp Tools



Tool Grade: Premium Crimp Tooling

Ratchet Configuration: Not Releasable, Not Adjustable

Die Sets Type: Fixed In Tool

Specification Type: TE Product Specification (114-)

TE Certification: Yes – Certificate Included

Features

Other

Crimp Form-Wire Barrel Type	Open Barrel - F Crimp
Tool Grade	Premium Crimp Tooling
Ratchet Configuration	Not Releasable, Not Adjustable
Die Sets Type	Fixed In Tool
Specification Type	TE Product Specification (114-)
TE Certification	Yes – Certificate Included
Power Technology Type	Battery, Manual
Tooling Type	Double Action Hand Tool

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Out of Scope
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	Not reviewed for China RoHS compliance
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC

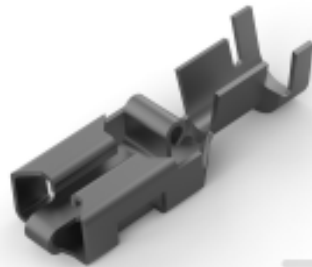
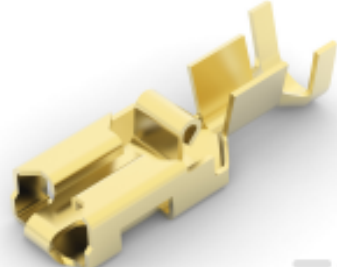

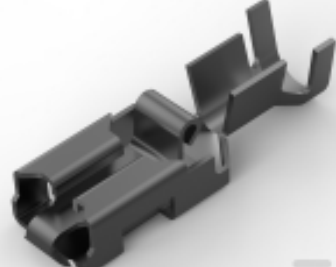
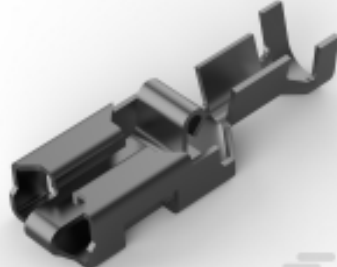


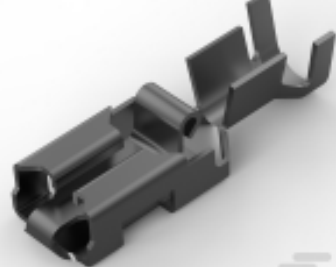
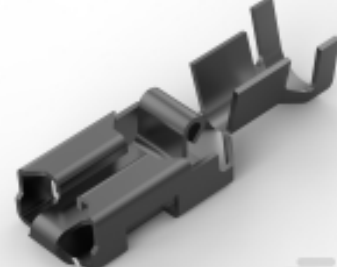
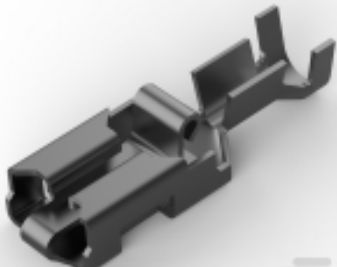
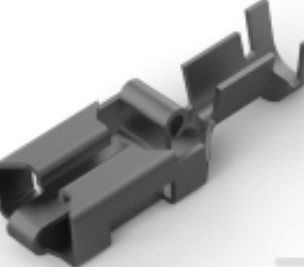
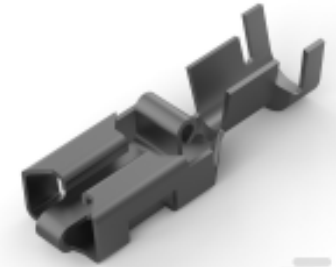


Halogen Content	Not Yet Reviewed for halogen content
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

### Compatible Parts

 <p>TE Part # 341001-6 PL 250 REC TERMINAL 13-11 PTPB LP</p>	 <p>TE Part # 154717-1 PL 250 REC TERMINAL 13-11 AWG BR</p>	 <p>TE Part # 737015-3 PL TERMINAL RECEPTACLE 4-6 MM2 PTPBR</p>	 <p>TE Part # 154717-7 PL 250 REC TERMINAL 13-11 AWG PTPPB</p>
 <p>TE Part # 154718-4 PL 250 REC TERMINAL 17-15 AWG TPPB</p>	 <p>TE Part # 154717-4 PL 250 REC TERMINAL 13-11 AWG TPPB</p>	 <p>TE Part # 790319-5 PL RECEPTACLE 3.3-6 MM2 TPPHBZ</p>	 <p>TE Part # 154717-6 PL 250 REC TERMINAL 14-11 AWG PTPB</p>
 <p>TE Part # 154717-3 PL 250 REC TERMINAL 14-11 AWG TPBR</p>	 <p>TE Part # 154718-6 250 PL MKI REC. 18-14AWG PTPB</p>	 <p>TE Part # 341002-6 PL 250 REC TERMINAL 18-14 PTPB LP</p>	 <p>TE Part # 341001-3 PL 250 REC TERMINAL 13-11 TPBR LP</p>



### Customers Also Bought



### Documents



### Product Drawings

[DAHT POSITIVE LOCK 18-11 ASSY](#)

English

---

### Datasheets & Catalog Pages

[CERTI-CRIMPPII-Premium-August-1-1773864-7](#)

English

[Crimp Term Whitepaper-Use the Right Tool 1-1773953-1](#)

English

### Bottoming Dies

English

[CRIMPING WHERE FORM MEETS FUNCTION](#)

English

---

### Instruction Sheets

[Double Action Hand Crimping Tool 525651](#)

English

[Instruction Sheet \(non U.S.\)](#)

English