



AMP

TE Internal #: 9-1478240-0

Portable Crimp Tools, Commercial Crimp Tooling, Operator Releasable & Adjustable, Removable/Interchangeable, Manual, SDE SA Frame Assembly

[View on TE.com >](#)

Application Tooling > Portable Crimp Tools



Tool Grade: **Commercial Crimp Tooling**

Ratchet Configuration: **Operator Releasable & Adjustable**

Die Sets Type: **Removable/Interchangeable**

TE Certification: **Upon Request for Fee**

Power Technology Type: **Manual**

**Features**

**Other**

Tool Grade	Commercial Crimp Tooling
Ratchet Configuration	Operator Releasable & Adjustable
Die Sets Type	Removable/Interchangeable
TE Certification	Upon Request for Fee
Power Technology Type	Manual
Tooling Type	SDE SA Frame Assembly

**Product Compliance**

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Not Compliant
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) SVHC > Threshold: Pb (.35% in Component Part)

**Article Safe Usage Statements:**  
Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.

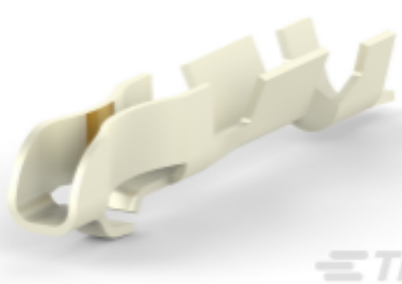

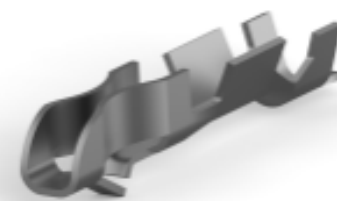
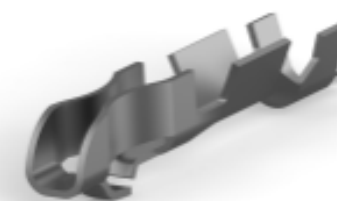










Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

### Compatible Parts

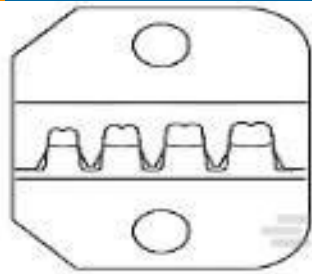
 <p>TE Part # 170204-4 170262-4 LP E1CRIMP SNAP IN</p>	 <p>TE Part # 130230 SOLIS R 12-10 6MM</p>	 <p>TE Part # 170204-1 EIS RECPT CONTACT</p>	 <p>TE Part # 170204-2 EIS CONTACT</p>
 <p>TE Part # 150072-1 22-16 PIDG R/T 7/16" STUD EXP</p>	 <p>TE Part # 696451-1 PIDG 22-16 K-D,NI-PL</p>	 <p>TE Part # 1-1377174-1 SMP 0-0165168-0</p>	 <p>TE Part # 322419 TERMINAL,BUDG R 16-14 4</p>
 <p>TE Part # 130232 SOLIS R 12-10 10MM</p>	 <p>TE Part # 1-1377174-7 SMP 0-0165049-0</p>	 <p>TE Part # 130228 SOLIS R 12-10 5MM</p>	 <p>TE Part # 1-2305020-2 PLUG ASSY, KEY B, CPA, HVA280-2PHI, 4MM2</p>



TE Part # 1-2305020-5  
PLUG ASSY, KEY E, CPA, HVA280-2PHI, 4MM2



TE Part # 1-322419-2  
BUDGET RING 16-14 6



TE Part # 1804039-1  
SDE DIE,RAYCHM 22-10



TE Part # 1976147-1  
SDE COMMERCIAL TOOL OR DIE



TE Part # 1976149-2  
SDE COMMERCIAL DIE SET



TE Part # 2063030-1  
SDE DIESET, RBY, UL



TE Part # 2063379-2  
SDE UMNL 0.5-2.0mm2 DIE



TE Part # 2063384-2  
SDE FASTON 250 1.0-2.5mm2 DIE

### Customers Also Bought



TE Part #1490413-3  
HYP10 SOLIS 4AWG NEST



TE Part #1490413-6  
HYP10 SOLIS 2/0AWG NEST



TE Part #1-1579007-8  
EXTRACTION TOOL



TE Part #1394512-1  
EINZELLEITDICHTG,BL



TE Part #11029805-00  
PIEZO FILM SENSORS WITH LEAD




TE Part #1-1564414-1  
HEAVY DUTY SEALED CONNECTOR HOUSINGS



TE Part #1-1625984-7  
Power Resistors: Aluminum Housed, HSA



TE Part #1-456402-5  
CRIMPER WIRE .055 F



TE Part #A58276-000  
TMS-101-RIB-4RPSCE-CS0016

### Documents



### Datasheets & Catalog Pages

[1-1773865-2\\_1015\\_Commercial Manual Hand Tools](#)

English

[1-1773732-4\\_DYNAMIC\\_SERIES\\_CATALOG\\_ENGLISH](#)

English

[Crimp Term Whitepaper-Use the Right Tool 1-1773953-1](#)

English

### Bottoming Dies

English

[CRIMPING WHERE FORM MEETS FUNCTION](#)

English

---

### Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English

[Instruction Sheet \(U.S.\)](#)

English