



Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts






TE Part # CAT-R21-731072
Bulbous Heat Shrink Boots: Lipped, Straight



TE Part # CAT-R21-D976
Dual Wall DWP-125 Spool HS Tubing



TE Part # CAT-R21-B3228
Single Wall RNF-100 Reel HS Tubing



TE Part # F46631-000
RMW-160/50-1200/ADH-0



TE Part # D70981-000
VERSAFIT-MINI-SPL-3/32-BK



TE Part # CX7205-000
RHW-48/12-1200/ADH-0



TE Part # 420356-000
RMW-35/12-1200/ADH-0



TE Part # 934922-000
RMW-75/22-1200/ADH-0



TE Part # C71645-000
RMW-10/3-1200/ADH-0



TE Part # CX7198-000
RHW-16/4-1200/ADH-0



TE Part # 397892-000
RMW-16/5-1200/ADH-0



TE Part # CX7208-000
RHW-12/3-1200/ADH-0



TE Part # 831991-000
382W042-25/225-0



TE Part # CX7202-000
RHW-24/6-1200/ADH-0



TE Part # CX6254-000
RHW-34/8-1200/ADH-0



TE Part # F64479-000
VERSAFIT-MINI-SPL-1/4-BK



TE Part # C17600-000
VERSAFIT-MINI-SPL-1/8-BK



TE Part # CB5025-000
BSTS-11X25-CL/NM




TE Part # F27135-000
VERSAFIT-MINI-SPL-3/16-BK



TE Part # CX7199-000
RHW-130/35-1200/ADH-0

Customers Also Bought



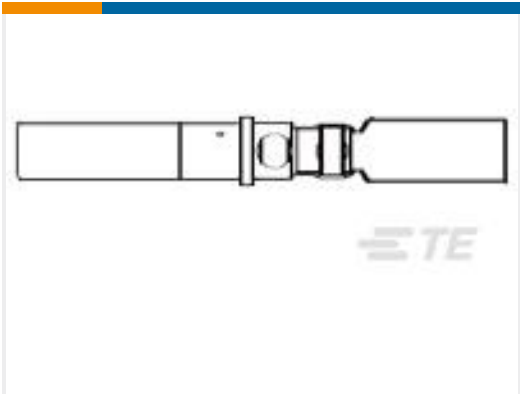

TE Part #152339-000
D-602-0123



TE Part #2176162-6
UPF25 0.1% 5PPM 1K0



TE Part #1622795-5
YR1 0.1% 4K02



TE Part #345774-000
STD SNAP-ON MARKERS



TE Part #D93040N001
HEAT SHRINK HALOGEN-FREE
CABLE BREAKOUTS



TE Part #1-528015-6
PISTOL GRIP HANDLE

Documents

Datasheets & Catalog Pages

Raychem Application Tooling

English

Agency Approvals

Agency Approval Document

English

Agency Approval Document

English