



Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Not Yet Reviewed
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	Not reviewed for China RoHS compliance
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Not Yet Reviewed
Halogen Content	Not Yet Reviewed for halogen content
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # G-NSDMG-016

[NS-5/DMG2-S ROHS](#)




Also in the Series | **MEAS D**




Tilt Sensors & Inclometers(1)

Customers Also Bought

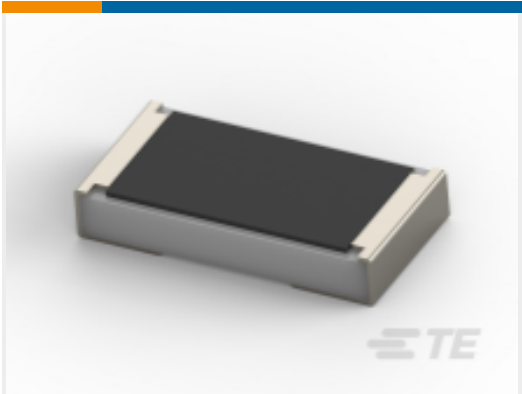

TE Part #1-2176231-2
SMD Power Resistor: 3 Watt, 1% Tol

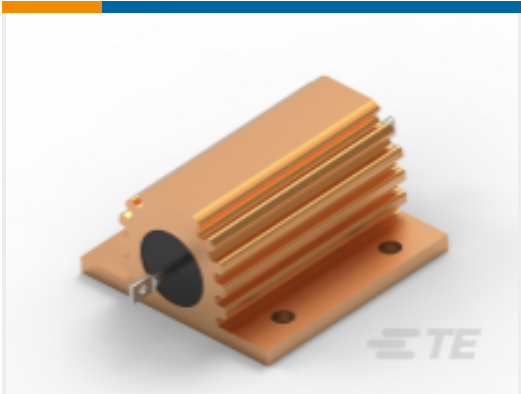

TE Part #1-1630019-9
Power Resistors: Aluminum Housed, HSA



TE Part #1630020-1
Power Resistors: Aluminum Housed, NHS




TE Part #1-1879208-3
CPF 0402 33R 0.1% 25PPM 1K RL




TE Part #1-1879136-9
RN 0603 20R 0.1% 10PPM 5K RL



TE Part #1219034002
MT2000-10.0-0-SP

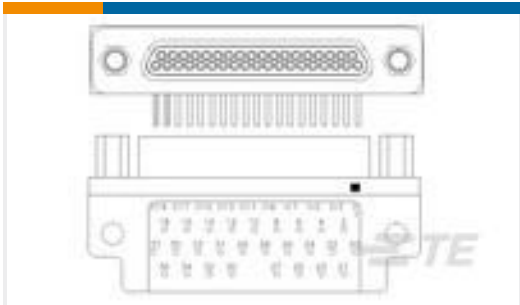

TE Part #1532255-4
M83513/10-F01NP = MCKS-N1-P-37PRT1

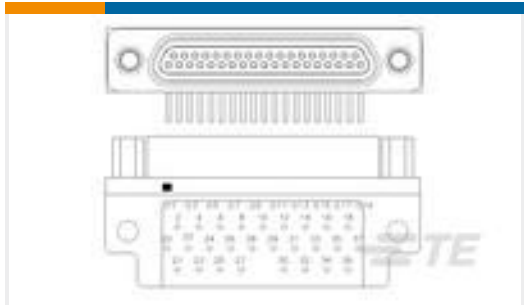

TE Part #1532263-1
M83513/13-F01CN = MCKS-C2-B-37SRT1



TE Part #YACT24MC35SN000000
JAM NUT RECEPTACLE

Documents

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_G-NSDMG-023_1.2d_dxf.zip

English

Customer View Model



[ENG_CVM_CVM_G-NSDMG-023_1.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_G-NSDMG-023_1.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[D_Series](#)

English