



Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2021 (211) SVHC > Threshold: Pb (3.7% in Component Part) <small>Article Safe Usage Statements: Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.</small>
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Wave solder capable to 265°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 1926720-2
AssyMINIPAKHDL2p15s2p RAplugBdlk

Customers Also Bought



TE Part #1658673-1
D-Sub Crimp: Plug, Signal, 62 Posn,
Pin Size 22, Shell Size 4



TE Part #177908-1
STD Temp Power Double Lock Cap




TE Part #177916-1
Power Double Lock Tab




TE Part #1658674-1
HDP-22,PLUG,SIZE 5,7,8 POSN



TE Part #163305-2
MATENLOK PIN SDW

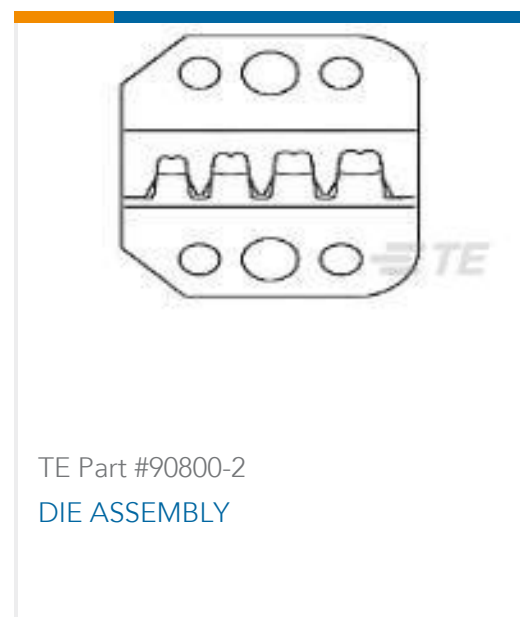


TE Part #90800-2
DIE ASSEMBLY

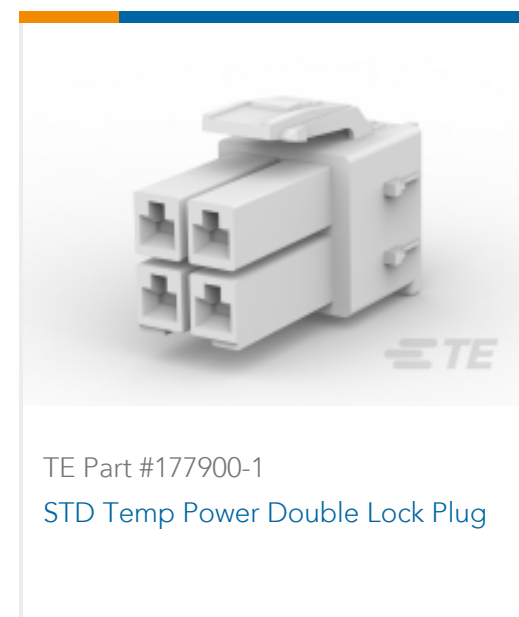

TE Part #177900-1
STD Temp Power Double Lock Plug



TE Part #2-520409-2
ULTRA-FAST 187 ASY REC 22-18 TPBR

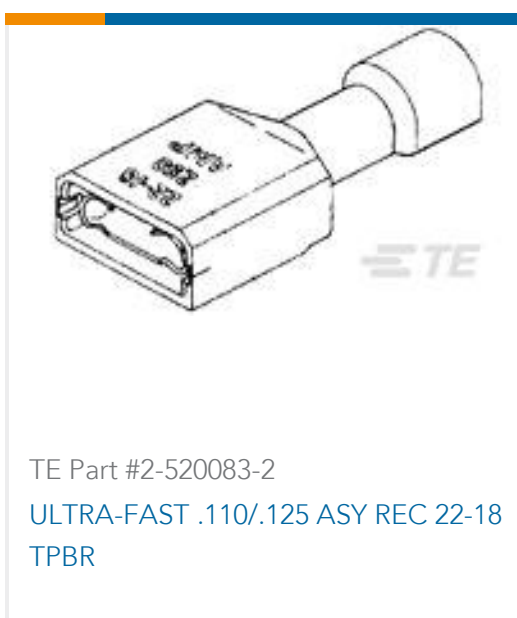

TE Part #2-520083-2
ULTRA-FAST .110/.125 ASY REC 22-18
TPBR



TE Part #1838893-1
M12 MtI MALE PNL CONN. Sldr Re

Documents

Product Drawings

[CONN SOCKET ASSY STRAIGHT SOLDER FLATPAQ](#)

English

CAD Files

[3D PDF](#)

[3D](#)



Customer View Model

[ENG_CVM_CVM_2085124-1_A.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2085124-1_A.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2085124-1_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Environmental Compliance

[Product Compliance](#)

English

[Product Compliance](#)

English