



Products Unlimited 4000 Series

TE Internal #: 2-1611447-1

TE Internal Description: 4000-09A19BB999=TRANSFORMER A
10 VA TRANSFORMERS

[View on TE.com >](#)



All 10 VA TRANSFORMERS (0)

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2019 (197) SVHC > Threshold: Not Yet Reviewed
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts





TE Part # 360042-1

250 FASTON HSG.,TAB,1 POS,
NATURAL



TE Part # 175022-1

250 PL EX REC. 18-14AWG PTBR

Also in the Series

Customers Also Bought




TE Part #6609027-4

CORCOM K SERIES SINGLE PHASE
FILTERS



TE Part #6-1609091-5

CORCOM FB SERIES SINGLE PHASE
FILTERS

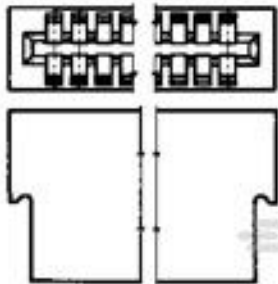

TE Part #1-583717-3

TW LEAF CRP HSG. 30-POS.



TE Part #1986716-7

Flush Mt Plug Spring Conn 7P 3.50mm




TE Part #2364568-2

AVH19 FLT SS LK NO LED 16A



TE Part #2364568-1

AVH19 FLT SS MT NO LED 16A

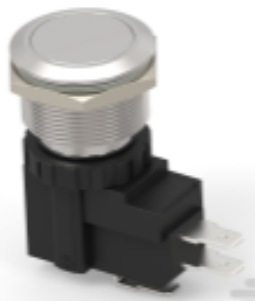


TE Part #2364684-1

AVH22 FLT SS MT NO LED 16A



TE Part #BGC880N0000052A000

917 RECEPTACLE, ANGLED,
ROTATABLE

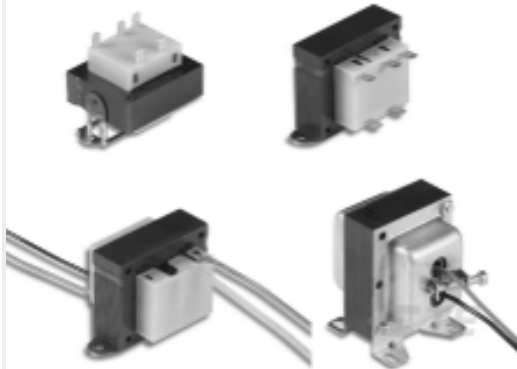

TE Part #5-1611457-5

CLASS II, UL 1585, 40VA CONTROL
TRANSFS

Documents

- Product Drawings

4000-09A19BB999=TRANSFORMER A

English
- CAD Files

3D PDF

3D



Customer View Model

[ENG_CVM_CVM_2-1611447-1_B.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2-1611447-1_B.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2-1611447-1_B.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[Transformers](#)

English

[Industrial Relays Quick Reference Guide](#)

English

[Industrial Relays Quick Reference Guide](#)

Japanese

[Industrial Relays Quick Reference Guide](#)