



All CLASS II, UL 1585, 40VA CONTROL TRANSFS (0)

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2021 (211) Candidate List Declared Against: JAN 2019 (197) SVHC > Threshold: Not Yet Reviewed
Halogen Content	Not Yet Reviewed for halogen content
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 61765-2
FASTON ADAPTER .250 REC TPBR




TE Part # 175022-1
250 PL EX REC. 18-14AWG PTBR

Also in the Series

Customers Also Bought



TE Part #1318912-1
EP CONN LP REC

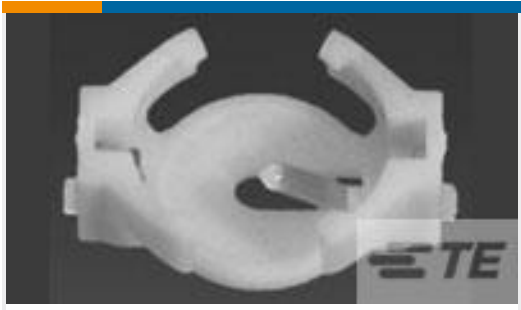

TE Part #1376164-1
BATTERY HOLDER ML621 ASSY



TE Part #1551631-5
1Shield Finger, Loose Piece




TE Part #1-1879208-8
CPF 0402 51R 0.1% 25PPM 1K RL



TE Part #1-66105-6
III+ SKT,24-20,TIN-LEAD,SMPACK



TE Part #2-1879355-9
RR03 5% 62K AMMO

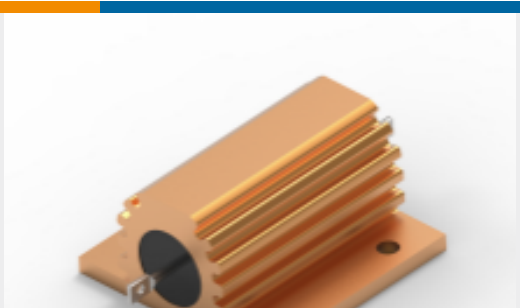

TE Part #1-1625984-7
Power Resistors: Aluminum Housed, HSA



TE Part #1618002-7
EV200AAANA=RELAY, EV200 SPST-N



TE Part #2305018-2
USB TYPE C, REC IPX8 ON BOARD DUAL SMT



TE Part #ZPF000000000147876
M39029/5-115

Documents

Product Drawings
4000-04E07AE999=TRANSFORMER

English

CAD Files
3D PDF

3D



Customer View Model

[ENG_CVM_CVM_5-1611454-6_A.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_5-1611454-6_A.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_5-1611454-6_A.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[Transformers](#)

English

[Industrial Relays Quick Reference Guide](#)

English

[Industrial Relays Quick Reference Guide](#)

Japanese

[Industrial Relays Quick Reference Guide](#)